


# H 1263 /...

Alarmkabel  
Alarmcable  
Câble de raccordement d'alarme

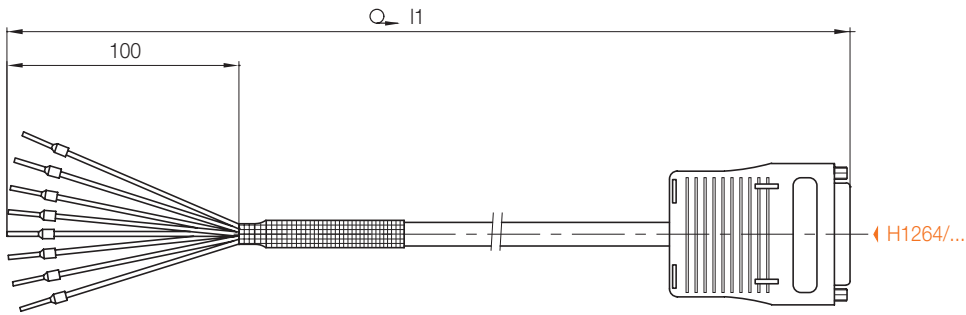


l1	Nr./No.
5000	H 1263 / 5000


# H 1224 /...

Buchseneinsatz  
Socket insert  
Doille


max. °C: 125  
DIN 16765 (HASCO Standard)

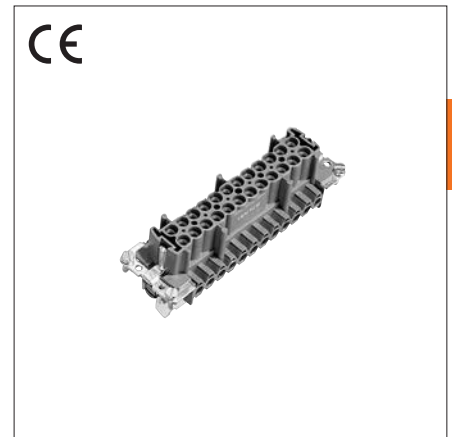

6

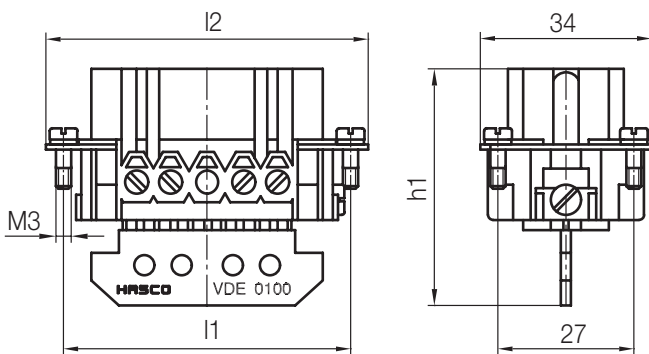

H12270/...  
H12271/...  
H12273/...

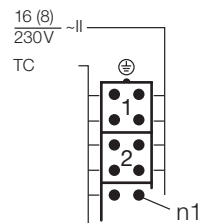

h1	l2	l1	Typ	I [A]	n1	Nr./No.
47	51	44	1	16	4	H1224/1/16/ 4
	64	57			8	8
52	84,5	77,5			16	16
	111	104			24	24