




H 1224/...

Buchseinsatz
Socket insert
Doille

max. °C: 125
DIN 16765 (HASCO Standard)

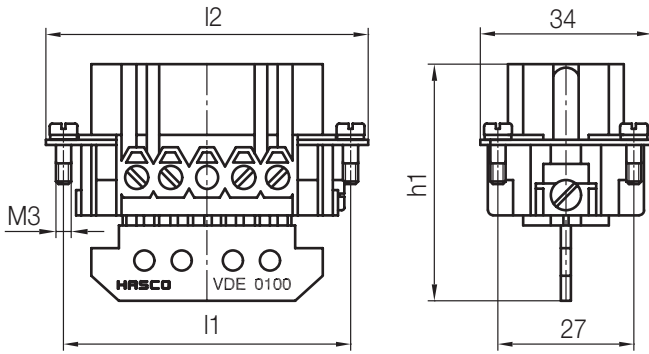

H12270/...
H12271/...
H12273/...

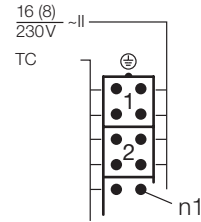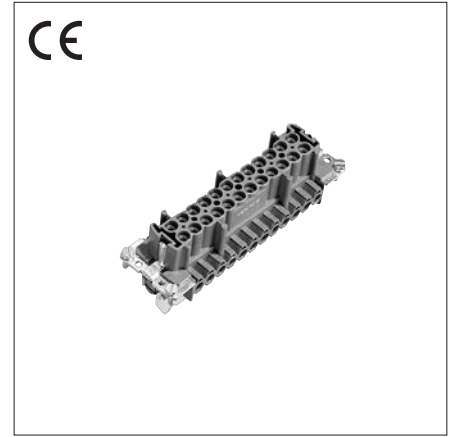


h1	l2	l1	Typ	I [A]	n1	Nr./No.
47	51	44	1	16	4	H 1224/1/16/ 4
	64	57			8	8
52	84,5	77,5			16	16
	111	104			24	24



H 12240/...

Buchseinsatz
Socket insert
Douille

DIN EN 61984, VDE 0627

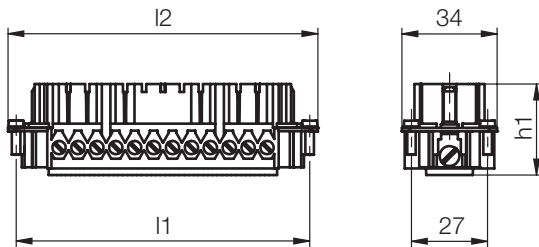

H12270/...
H12271/...
H12273/...

 
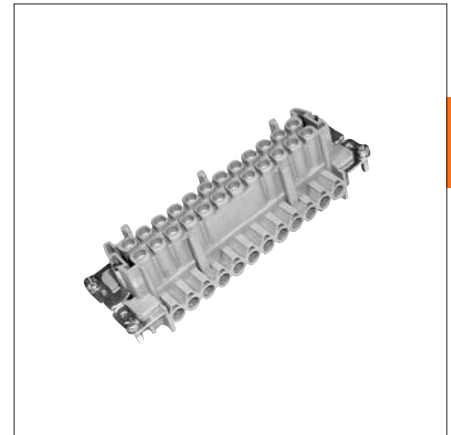


h1	l2	l1	Typ	I [A]	n1	Nr./No.
34,6	51	44	1	16	6	H 12240/1/16x 6
	64	57			10	10
	84,5	77,5			16	16
	111	104			24	24


H 12241/...

Buchseneinsatz, schmal
Socket insert, small
Douille, étroit

DIN EN 61984, VDE 0627

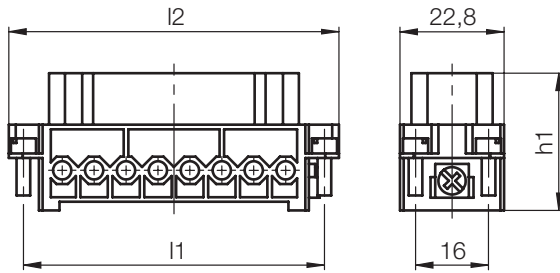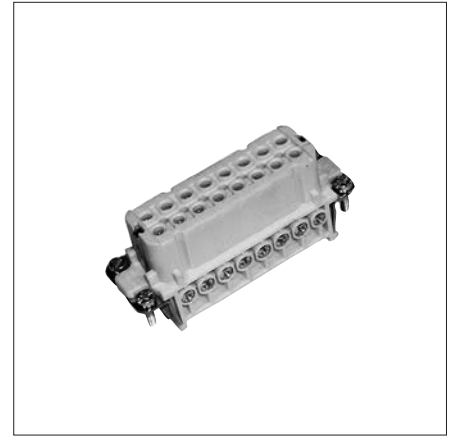

H12272/...

 

h1	l2	l1	Typ	I [A]	n1	Nr./No.
30,1	56	49,5	1	16	10	H 12241/1/16x 10
	72,4	66			16	16