
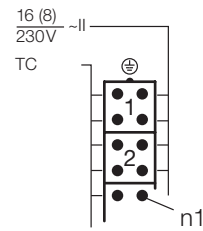


# H 1225 /...

Kraft-/Signal-Kabel  
 Connecting power-/signal cable  
 Câble de connexion force/signal

max. °C: 125  
 DIN 16765 (HASCO Standard)

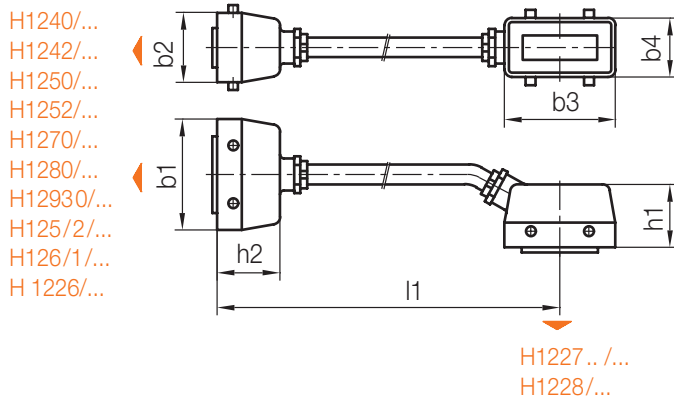



Sonderlängen auf Anfrage  
 Other lengths on request  
 Longueurs spécifiques sur simple demande

h2	h1	b4	b3	b2	b1	I [A]	n1	l1	Nr./No.
47,5	47,5	43	60	43	60	16	4	2500	H1225/16x 4x2500
53	53		73		73		8		8x2500
60	60		95		95		16		16x2500
70	70		120		120		24		3000

# H 1226/...

Kraft-/Signal-Adapter  
 Power-/signal adapter  
 Adapteur de câble force/signal

max. °C: 125  
 DIN 16765 (HASCO Standard)

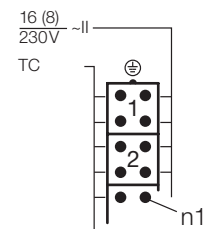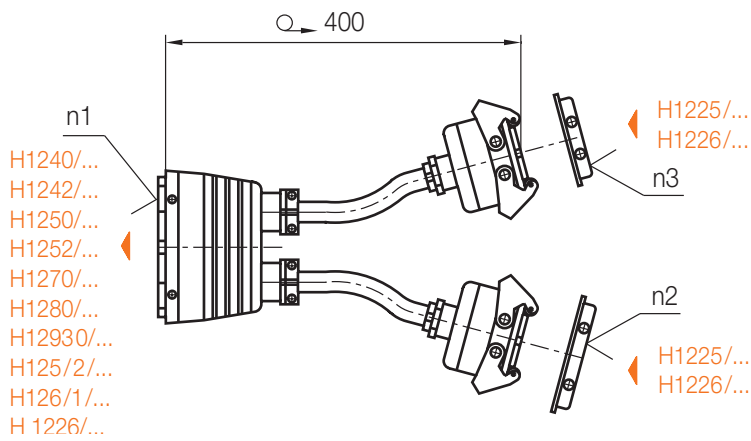

I [A]	n1	n2	n3	Nr./No.
16	8	4	4	H1226/16x 8x 4x4
	16	8	8	16x 8x8
	24	16		24x16x8