




# H 1229 /...

Steckereinsatz  
Plug insert  
Connecteur

max. °C: 125  
DIN 16765 (HASCO Standard)  
VDE 0100

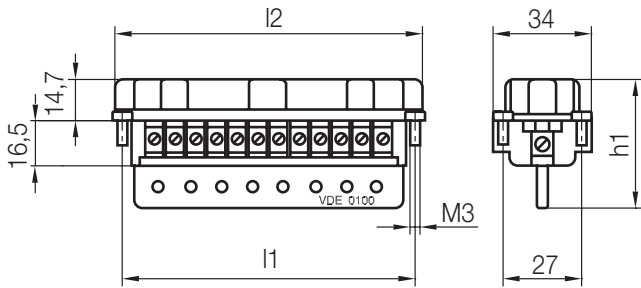

H12270/...  
H12271/...  
H12273/...

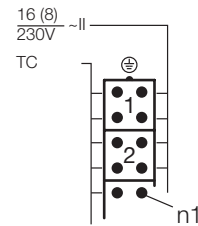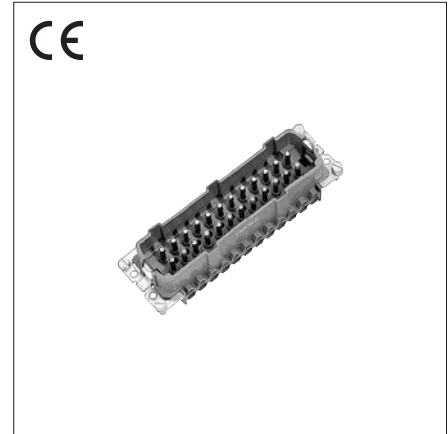


h1	l2	l1	Typ	I [A]	n1	Nr./No.
46,2	51	44	1	16	4	H 1229/1/16x 4
	64	57			8	8
51,2	84,5	77,5			16	16
	111	104			24	24


# H 12290 /...

Steckereinsatz  
Plug insert  
Connecteur

DIN EN 61984, VDE 0627

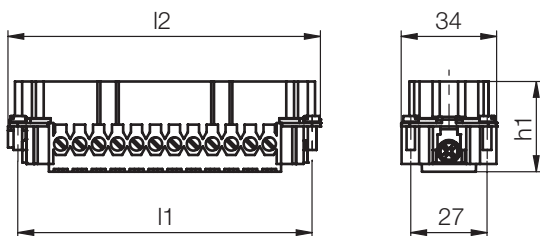

H12270/...  
H12271/...  
H12273/...

 

h1	l2	l1	Typ	I [A]	n1	Nr./No.
32,4	51	44	1	16	6	H 12290/1/16x 6
	64	57			10	10
	84,5	77,5			16	16
	111	104			24	24