
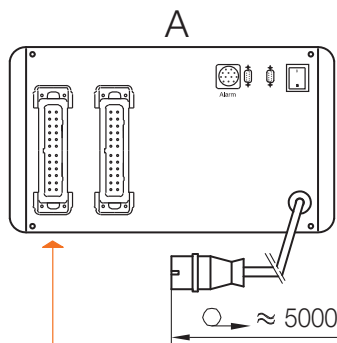
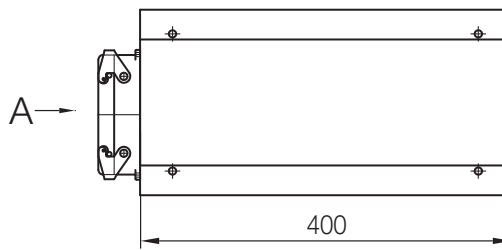
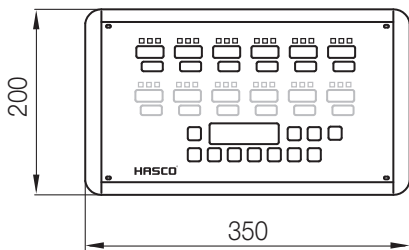


# H 12930 /...


Mehrzonen-Regler  
Multi-zone control unit  
Régulateur multizones

400 V 3 N ~ ±10% / 50Hz

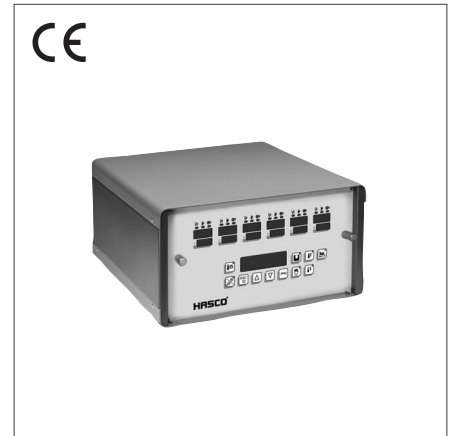

H1225/16/24/3000

n<sub>1</sub> = Regelzonen  
Control zones  
Zones de réglage

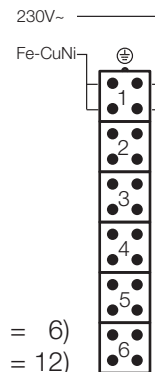

x 1 (n<sub>1</sub> = 6)  
x 2 (n<sub>1</sub> = 12)

Kontaktbelegung nach DIN 16765 –  
Individuelle Belegung auf Anfrage.

Allocation of pin connection according to DIN 16765 –  
Customised allocation on request.

Attribution des broches conformément à la norme DIN 16765 –  
Brochage personnalisé sur demande.



**Neu / New / Nouveau**

P [W]	n <sub>1</sub>	I [A]	Nr./No.
max. 21600	6	max. 16	H12930/ 6x16
	12		12x16


# H 12930 /...

Mehrzonen-Regler  
Multi-zone control unit  
Régulateur multizones

400 V 3 N ~ ±10% / 50Hz

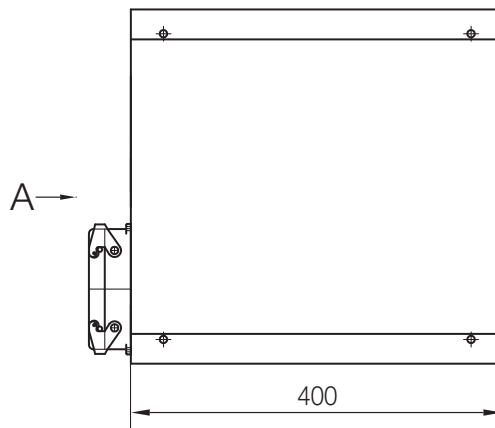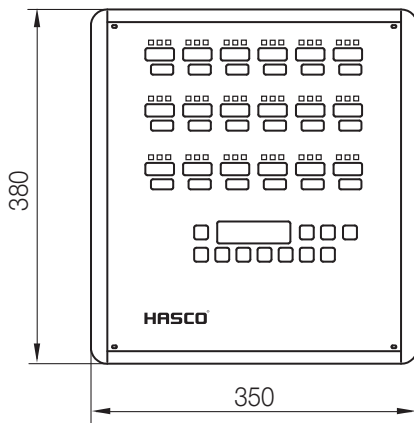


A

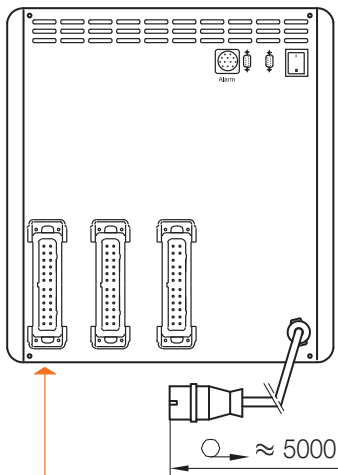

H1225/16/24/3000

n1 = Regelzonen  
Control zones  
Zones de réglage

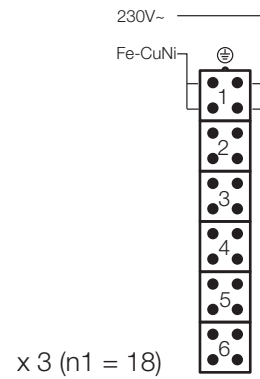

Kontaktbelegung nach DIN 16765 –  
Individuelle Belegung auf Anfrage.

Allocation of pin connection according to DIN 16765 –  
Customised allocation on request.

Attribution des broches conformément à la norme DIN 16765 –  
Brochage personnalisé sur demande.

Neu / New / Nouveau

P [W]	n1	I [A]	Nr./No.
max. 21600	18	max. 16	H12930/18x16