


Techni Shot

Heißkanaldüse

Hot runner nozzle

Buse á canal chaud

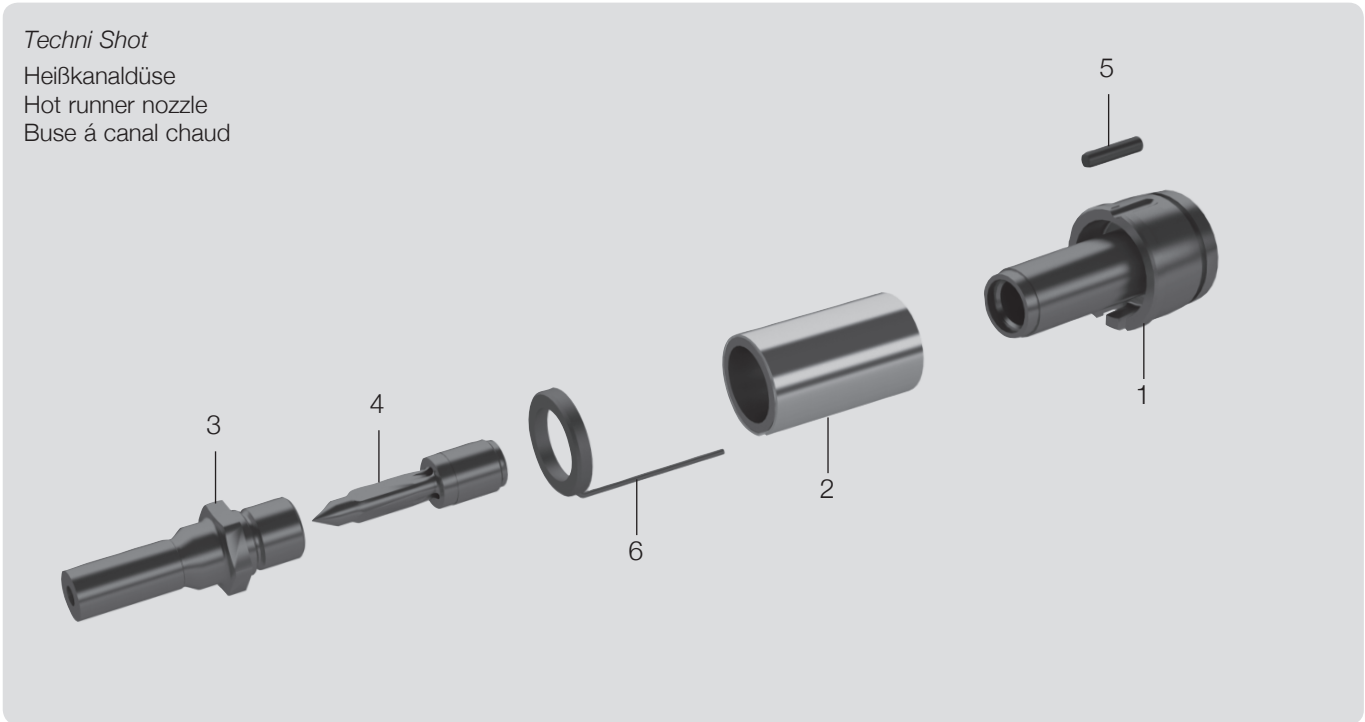

Pos.	1	2	3	4	5	6
H332012 / ...		H33061 / ...		(CuCoBe)	Z25 / ...	H3305 / ...
...25x 56	H33001 / 25x 56	...25x 56	H33225 / 25x1,4	H33214 / 25	...3x14	...25x 56
63	63	63				63
71	71	71				71
80	80	80				80
100	100	100				100
125	125	125				125
...32x 63	H33000 / 32x 63	...32x 63	...32x1,6	H33211 / 32	...5x14	...32x 63
71	71	71				71
80	80	80				80
90	90	90				90
100	100	100				100
125	125	125				125
...40x 80	...40x 80	...40x 80	...40x1,9	...40	...6x14	...40x 80
90	90	90				90
100	100	100				100
112	112	112				112
125	125	125				125
140	140	140				140
...50x 100	...50x 100	...50x 100	...50x2,2	...50		...50x 100
112	112	112				112
125	125	125				125
140	140	140				140
160	160	160				160
200	200	200				200
250	250	250	250			
...60x 125	...60x 125	...60x 125	H33226 / 60x4	...60	...6x24	...60x 125
140	140	140				140
160	160	160				160
200	200	200				200
250	250	250				250
300	300	300				300

Ersatzteile/Spare parts/Pièces détachées

Pos.	Benennung	Designation	Désignation	Stück Quantity Pièce
1	Düsenkörper	Nozzle body	Corps de buse	1
2	Heizung	Heater	Elément chauffant	1
3	Vorkammer lang	Melt chamber long	Elément pré-chambre long	1
4	Torpedospitze	Nozzle tip	Pointe torpédo	1
5	Zylinderstift	Dowel pin	Goupille cylindrique	1
6	Thermofühler	Thermocouple	Thermocouple	1

Pos.	1	2	3	4	5	6
H332052/...		H33061/...		H33215/... (TZM)	5 Z25/...	6 H3305/...
...25x 56	H33001/25x 56	...25x 56	H33225/ 25x1,4	...25	...3x14	...25x 56
63	63	63				63
71	71	71				71
80	80	80				80
100	100	100				100
125	125	125				125
...32x 63	H33000/32x 63	...32x 63	H33226/ 32x1,6	...32	...5x14	...32x 63
71	71	71				71
80	80	80				80
90	90	90				90
100	100	100				100
125	125	125				125
...40x 80	...40x 80	...40x 80	H33225/ 40x1,9	...40	...6x14	...40x 80
90	90	90				90
100	100	100				100
112	112	112				112
125	125	125				125
140	140	140				140
...50x100	...50x100	...50x100	...50x2,2	...50		...50x100
112	112	112				112
125	125	125				125
140	140	140				140
160	160	160				160
200	200	200				200
250	250	250	250			
...60x125	...60x125	...60x125	H33226/ 60x4	...60	...6x24	...60x125
140	140	140				140
160	160	160				160
200	200	200				200
250	250	250				250
300	300	300				300