


H6242 /...

Vario Shot®
Mono-Düse
Mono nozzle
Monobuse

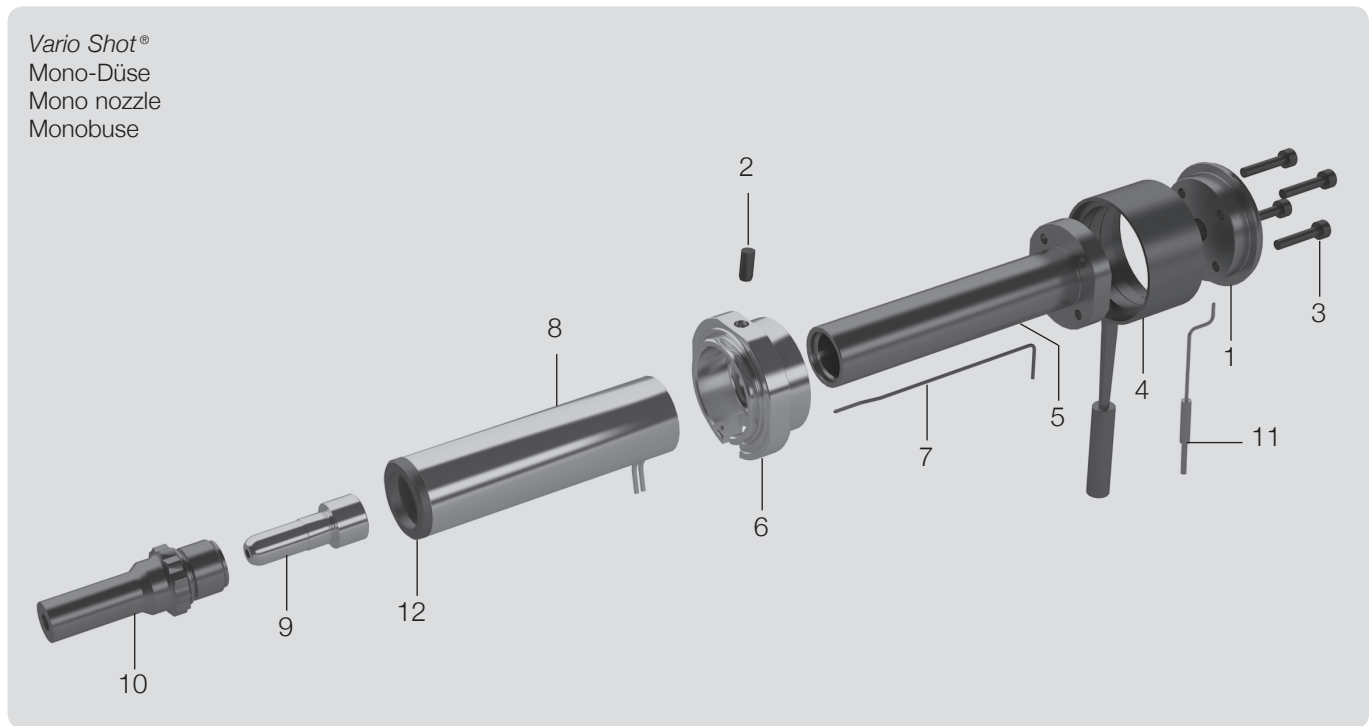



Pos.	1		1		1	2	3
H6242/...	H6204/...	H6242/... (sr1 = 15,5)	H6204/... (sr1 = 15,5)	H6242/... (sr1 = 40)	H6204/... (sr1 = 40)	Z25/...	Z31/...
...25x 66	...25	...25x 66x15,5	...25x15,5	...25x 66x40	...25x40	...3x10	...3x16
73		73		73			
81		81		81			
90		90		90			
110		110		110			
135		135		135			
150		150		150			
170		170		170			
...32x 73	...32	...32x 73x15,5	...32x15,5	...32x 73x40	...32x40	...4x10	
81		81		81			
90		90		90			
100		100		100			
110		110		110			
135		135		135			
150		150		150			
170		170		170			
...40x 90	...40	...40x 90x15,5	...40x15,5	...40x 90x40	...40x40	...4x14	...4x16
100		100		100			
110		110		110			
122		122		122			
135		135		135			
150		150		150			
170		170		170			
190		190		190			
210		210		210			
...50x 115	...50	...50x 115x15,5	...50x15,5	...50x 115x40	...50x40	...5x12	...5x25
127		127		127			
140		140		140			
155		155		155			
175		175		175			
215		215		215			
265		265		265			
315		315		315			

Pos.	Benennung	Designation	Désignation	Stück Quantity Pièce
1	Adapterscheibe	Adapter disc	disque d'adaptateur	1
2	Zylinderstift	Dowel pin	Goupille cylindrique	1
3	Zylinderschraube	Socket head cap screw	Vis à tête cylindrique à six pans creux	4
4	Kopfheizung	Heater for nozzle head	Élément chauffant pour tête de buse	1
5	Düsenkörper	Nozzle body	Corps de buse	1
6	Düsenkopf	Nozzle head	Tête de buse	1
7	Thermofühler	Thermocouple	Thermocouple	1
8	Heizung	Heater	Élément chauffant	1
9	Torpedospitze	Nozzle tip	Pointe torpédo	1
10	Vorkammer lang	Pre-chamber long	Écrou long	1
11	Thermofühler	Thermocouple	Thermocouple	1
12	Fühlerring	Sensor ring	Anneau de sonde	1

Pos. 1: H6204/d1



Pos. 1: H6204/d1 x sr1

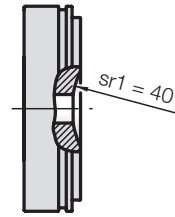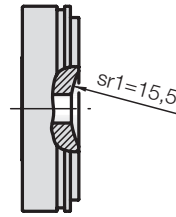

4	5	6	7	8	9	10	11	12
H6203/...	H6001/...	H6201/...	H1295/6/...	H6002/...	H6040/...	H6090/...	H1295/5/...	H6003/...
...2532	...25x 56 63 71 80 100 125 140 160 ...32x 63 71 80 90 100 125 140 160	...25 ...32	...1x 55 ...1x 65 ...1x 75 ...1x 95 ...1x120 ...1x135 ...1x155 ...1x 55 ...1x 65 ...1x 75 ...1x 84 ...1x 95 ...1x120 ...1x135 ...1x155	...25x 56 63 71 80 100 125 160 ...32x 63 71 80 90 100 125 140 160	...25 ...32	...25 ...32	...1x45	...25 ...32 ...40
...40	...40x 80 90 100 112 125 140 160 180 200	...40	...1x 75 ...1x 84 ...1x 95 ...1x110 ...1x120 ...1x135 ...1x155 ...1x175 ...1x195	...40x 80 90 100 112 125 140 160 180 200	...40	...40		...40
...50	...50x100 112 125 140 160 200 250 300	...50	...1x 84 ...1x 95 ...1x110 ...1x135 ...1x155 ...1x195 ...1x235 ...1x285	...50x100 112 125 140 160 200 250 300	...50	...50		...50