
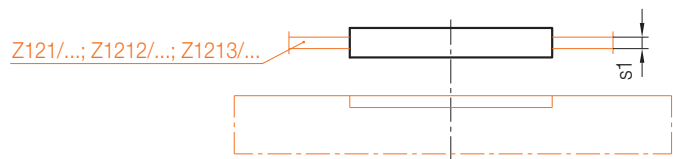
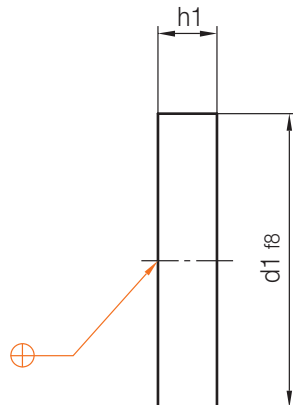


# K 505 /...

Zentrierflansch, ohne Ansatz  
 Locating ring, straight  
 Rondelle de centrage, sans plot

Mat.: 1.1730 / 640 N/mm<sup>2</sup>

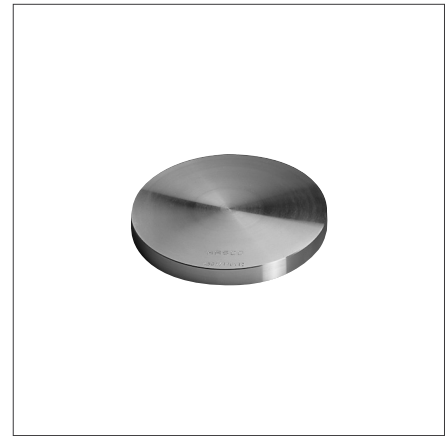

**Neu/New/Nouveau**

s1	d1	h1	Nr./No.
-	40	6	K 505/ 40x 6
3		9	40x 9
-	60	8	K 505/ 60x 8
3		11	60x11
5		13	60x13
-	80	8	K 505/ 80x 8
3		11	80x11
5		13	80x13
-	90	8	K 505/ 90x 8
3		11	90x11
-		12	90x12
5		13	90x13
7		15	90x15
8,5		16,5	90x16,5
-	100	8	K 505/ 100x 8
		12	100x12

s1	d1	h1	Nr./No.
-	110	8	K 505/ 110x 8
		12	110x12
	120	8	K 505/ 120x 8
		12	120x12
	125	8	K 505/ 125x 8
		12	125x12
	130		K 505/ 130x12
		140	140x12
	150	8	K 505/ 150x 8
		12	150x12
	160	8	K 505/ 160x 8
		12	160x12
	175	8	K 505/ 175x 8
		12	175x12
	200	8	K 505/ 200x 8
		12	200x12
	250		250x12