


# Z01003/...

Linearführungseinheit  
 Linear ball bearing unit  
 Unité de guidage à bille linéaire

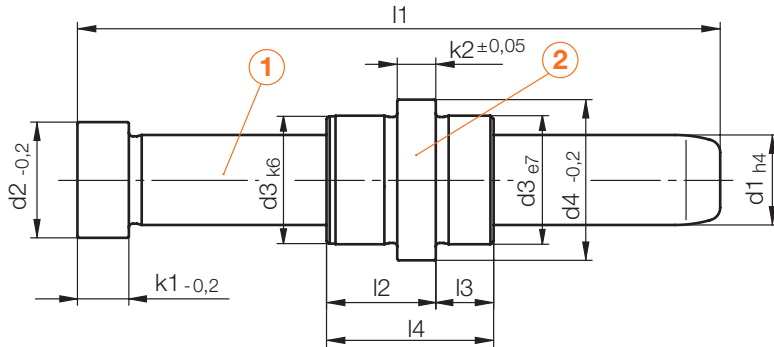


Pos 2 Z13/...	Pos 1 Z0100/...	k2	k1	l4	d4	d3	d2	d1	l1	l2	l3	Nr./No.
12x17x 9	12x 80	6	6	26	28	24	16	12	80	17	9	Z01003/12x 80x17x 9
	100											100
	120											120
	140											140
	160											160
	160											160
12x17x12	12x 80			29					80		12	Z01003/12x 80x17x12
	100											100
	120											120
	140											140
	160											160
	160											160
18x22x12	18x100	8		34	36	32	22	18	100	22	12	Z01003/18x 100x22x12
	120											120
	140											140
	160											160
	180											180
	180											180
18x22x17	18x100			39					100		17	Z01003/18x 100x22x17
	120											120
	140											140
	160											160
	180											180
	180											180
24x17x12	24x120	15		29	43	39	28	24	120	17	12	Z01003/24x 120x17x12
	140											140
	160											160
	180											180
	200											200
	220											220
	240											240
	300											300
	300											300
24x27x17	24x120			44					120	27	17	Z01003/24x 120x27x17
	140											140
	160											160

# Z01003/...

Linearführungseinheit  
 Linear ball bearing unit  
 Unité de guidage à bille linéaire



1

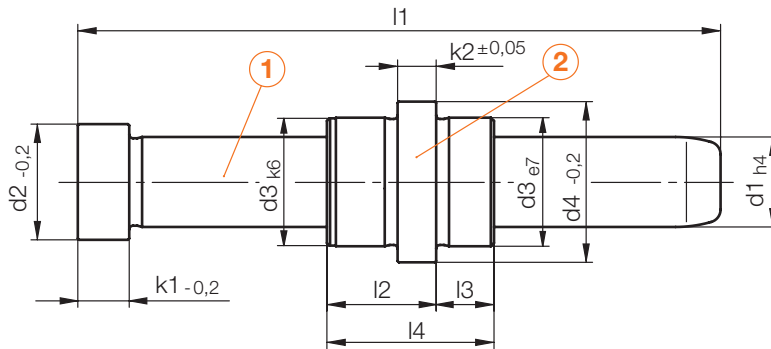

Pos 2 Z13/...	Pos 1 Z0100/...	k2	k1	l4	d4	d3	d2	d1	l1	l2	l3	Nr./No.
24x27x17	24x180	6	15	44	43	39	28	24	180	27	17	Z01003/24x 180x27x17
	200											200
	220											220
	240											240
	300											300
24x27x22	24x120			49					120		22	Z01003/24x 120x27x22
	140											140
	160											160
	180											180
	200											200
	220											220
	240											240
	300											300
30x22x17	30x120			39	54	50	36	30	120	22	17	Z01003/30x 120x22x17
	160											160
	200											200
	240											240
	300											300
30x32x22	30x120			54					120	32	22	Z01003/30x 120x32x22
	160											160
	200											200
	240											240
	300											300
30x36x27	30x120			63					120	36	27	Z01003/30x 120x36x27
	160											160
	200											200
	240											240
	300											300
	360								360			360