
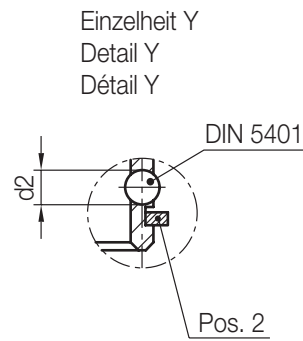


Z1201/...

Kugelkäfig, mit Sicherungsring
 Ball cage, with circlip
 Cage à billes, avec circlip

Mat.: 2.0401

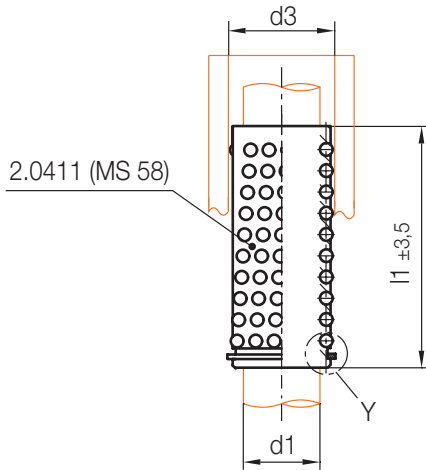

Pos. 1 Z67/...	d3	d2	d1	l1	Nr./No.
14x1	15	2	11	40	Z1201/11x 40
				56	56
15x1	16		12	40	12x 40
				56	56
20x1,2	21	3	15	45	Z1201/15x 45
				56	56
				63	63
				71	71
21x1,2	22		16	45	16x 45
				56	56
				63	63
				71	71
24x1,2	25		19	31	Z1201/19x 31
				45	45
				56	56
				63	63
				71	71
				80	80
				95	95
25x1,2	26		20	31	Z1201/20x 31
				45	45
				56	56
				63	63
				71	71
				80	80
29x1,5	30		24	31	Z1201/24x 31
				45	45
				56	56
				63	63
				71	71
				80	80
				80	80

Pos. 1 Z67/...	d3	d2	d1	l1	Nr./No.
29x1,5	30	3	24	95	Z1201/24x 95
				120	120
30x1,5	31		25	31	Z1201/25x 31
				45	45
				56	56
				63	63
				71	71
				80	80
37x1,75	38	4	30	40	Z1201/30x 40
				50	50
				56	56
				71	71
				80	80
				95	95
39x1,75	40		32	40	Z1201/32x 40
				50	50
				56	56
				71	71
				80	80
				95	95
				105	105
45x1,75	46		38	45	Z1201/38x 45
				50	50
				105	105
				120	120
				140	140
				160	160


Z 1201/...

Kugelkäfig, mit Sicherungsring
 Ball cage, with circlip
 Cage à billes, avec circlip

Mat.: 2.0401



1

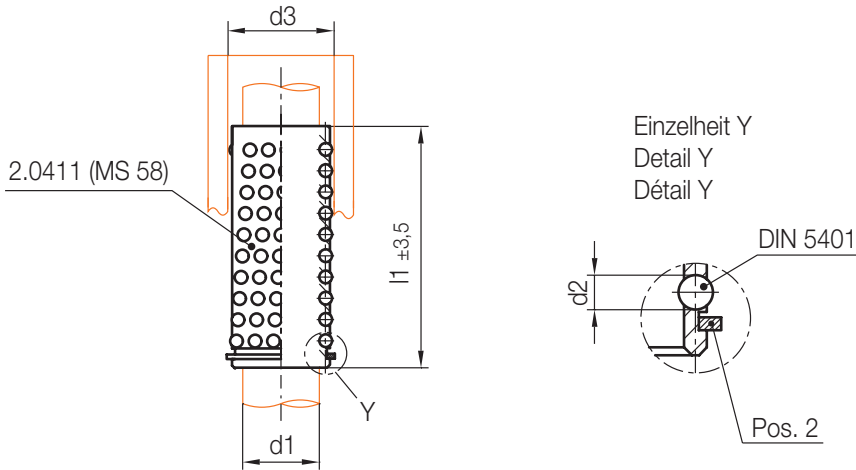

Pos. 1 Z67/...	d3	d2	d1	l1	Nr./No.
45 x 1,75	46	4	38	56	Z 1201/38x 56
				63	63
				80	80
				95	95
				105	105
				120	120
				140	140
				160	160
				180	180
				200	200
				240	240
				47 x 1,75	48
50	50				
56	56				
63	63				
80	80				
95	95				
105	105				
120	120				
140	140				
160	160				
180	180				
200	200				
240	240				
55 x 2	56		48	50	Z 1201/48x 50
				63	63
				80	80
				95	95
				105	105
				120	120
				140	140
				160	160

Pos. 1 Z67/...	d3	d2	d1	l1	Nr./No.
55 x 2	56	4	48	180	Z 1201/48x 180
				200	200
				240	240
				50	50 x 50
57 x 2	58		50	50	50 x 50
				63	63
				80	80
				95	95
				105	105
				120	120
				140	140
				160	160
67 x 2,5	68		60	95	Z 1201/60x 95
				105	105
				120	120
				140	140
				160	160
				180	180
				200	200
				240	240
70 x 2,5	71		63	95	63 x 95
				105	105
				120	120
				140	140
				160	160
				180	180
				200	200
				240	240