


Z1471/...

Näherungsschalter, induktiv, mit Außengewinde
 Inductive proximity switch, threaded
 Déclencheur de proximité, à induction, avec filetage extérieur

~ 10 ... 30V / % 300 mA
 max. C°: 70



Aktive Fläche
 Active surface
 Surface active

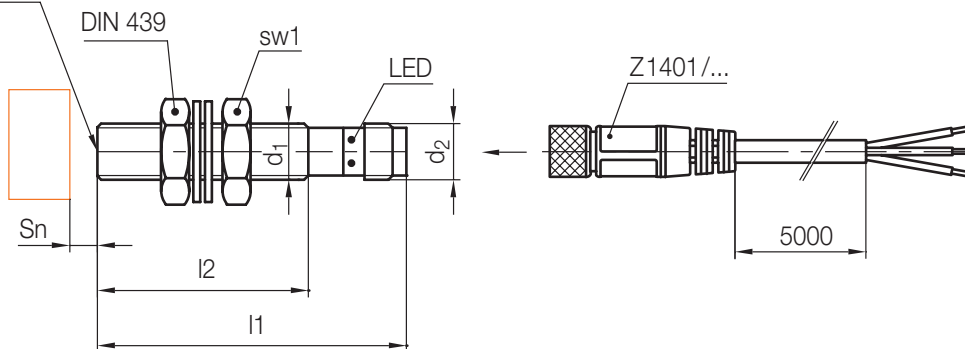

sw1	l2	l1	d2	Sn	d1	Nr./No.
7	20	41	M 8x1	1,5	M 5x0,5	Z1471/1,5x 5x0,5
13	30,5	45	M 8x1	2	M 8x1	2 x 8x1
17	50	65	M12x1		M12x1	2 x 12x1