
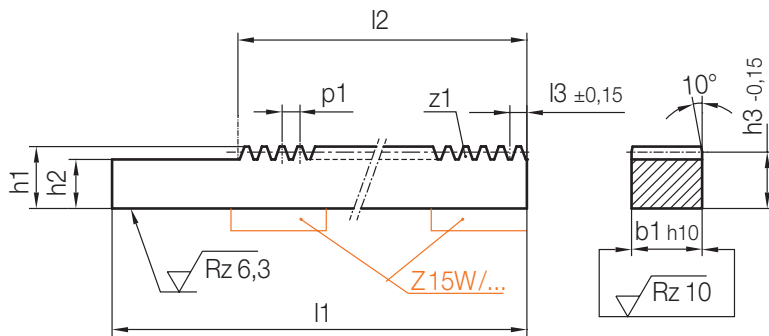


# Z 1540 /...

Zahnstange  
Rack  
Crémaillère

Mat.: 1.7225/1080 N/mm<sup>2</sup>

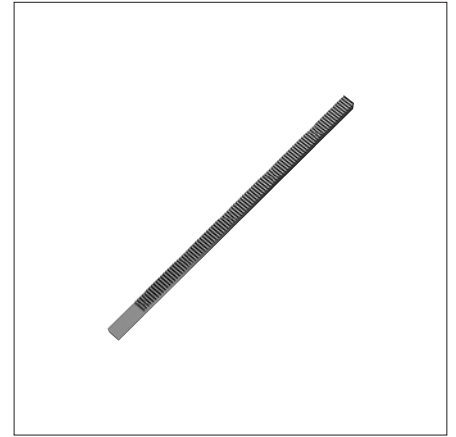

4

m1 = Modul/Module/Module  
z1 = Zähnezahl/Number of teeth/  
Nobre de dents

p1	z1	h3	h2	h1	l3	l2	b1	l1	Tol. l1	m1	Nr./No.
3,142	90	12,5	11,2	13,5	2,9	282,5	16	315	+ 0,5	1	Z 1540/16x 315x1
	117					367,7		400			400
	149					467,9		500			500
	190					596,7		630			630
3,927	92	16	14,4	17,25	3,7	361,1	18	400		1,25	Z 1540/18x 400x1,25
	117					459,3		500			500
	150					588,8		630			630
	193					757,7		800			800
4,712	95	18	16,1	19,5	4,5	447,5	20	500	+ 1	1,5	Z 1540/20x 500x1,5
	123					579,4		630			630
	159					749,1		800			800
6,283	90	20	17,5	22	6	565,2	25	630		2	Z 1540/25x 630x2
	117					734,9		800			800
	149					935,9		1000			1000
7,854	92	25	21,8	27,5	7,6	722,3	28	800		2,5	Z 1540/28x 800x2,5
	117					918,7		1000			1000
	149					1170		1250			1250