



# Z18/...

Führungsblock  
Guide block  
Bloc de guidage



Mat.: 1.2162 60HRC

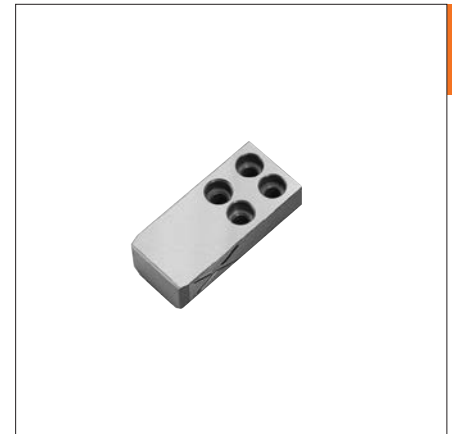


1

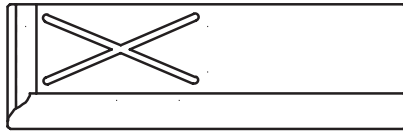

Typ 2

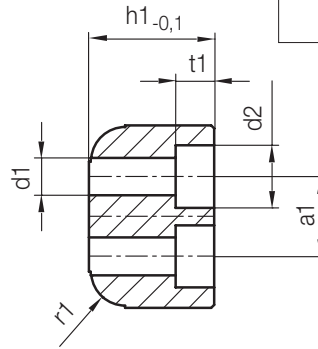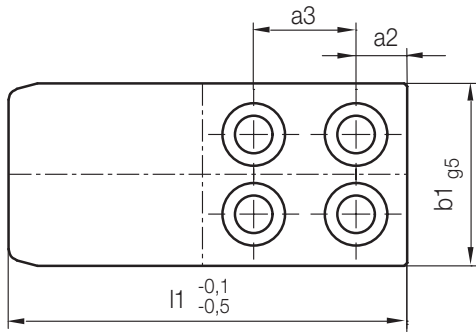

Typ 1



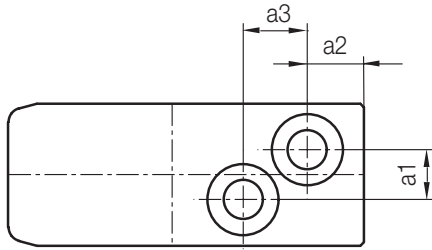


Typ	r1	t1	a3	a2	a1	d2	d1	b1	s1	h1	Nr. / No.
1	6	5,7	9	8	7	10	5,5	20	18	50	Z18/ 20x18x 50
										75	75
										90	90
2	8	6,8	18	9	14	11	6,6	32	22	70	Z18/ 32x22x 70
										90	90
										112	112
										125	125
										150	150
										150	150
	10	9	21	12	24	15	9	50	30	90	Z18/ 50x30x 90
										125	125
										150	150
										175	175
										200	200
										200	200
12	11	26	15	30	18	11	63	32	112	Z18/ 63x32x112	
									150	150	
									175	175	
									200	200	
									250	250	
									250	250	
	12	44	80	35	112	Z18/ 80x35x112					
					150	150					
					175	175					
					200	200					
					250	250					
					250	250					
15	13	32	18	55	20	13,5	100	50	175	Z18/100x50x175	
									200	200	
									250	250	
	35	20	75	120	65	200	Z18/120x65x200				
						250	250				
						300	300				

# Z19/...

Führungsbacke  
Guide jaw  
Sabot de guidage

Mat.: 1.2162 58HRC

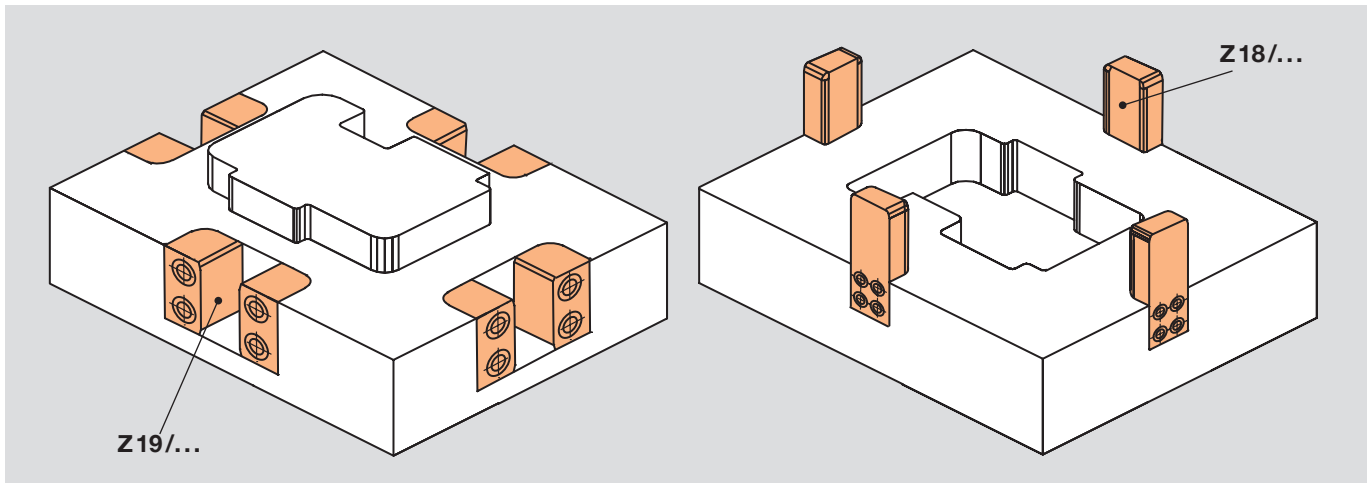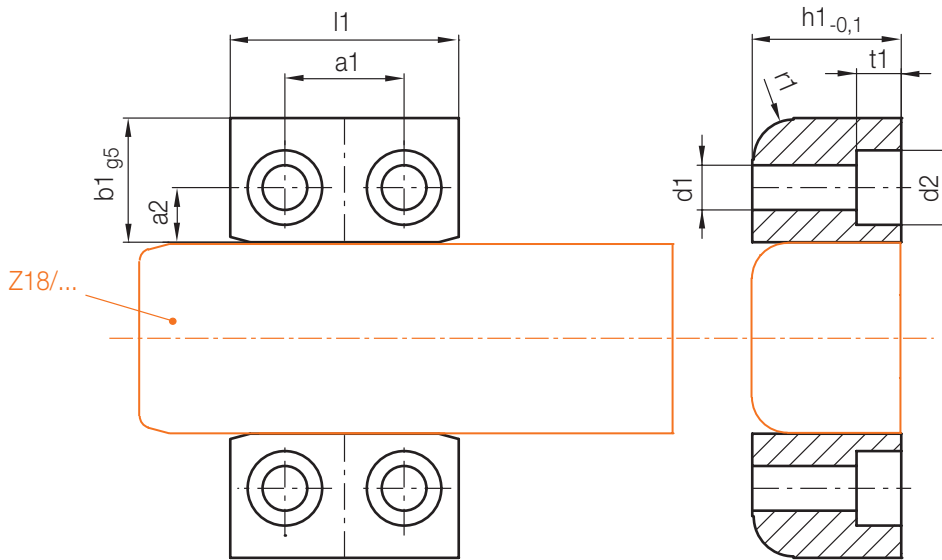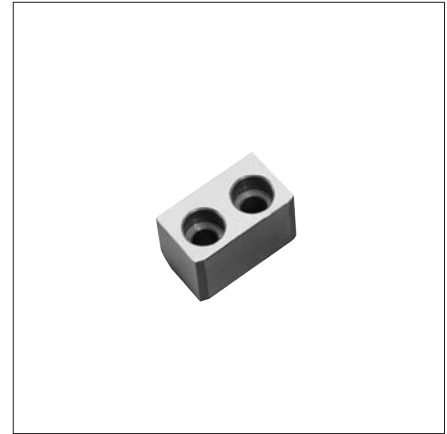



r1	t1	a2	a1	d2	d1	b1	h1	l1	Nr./No.
6	5,7	8	12	10	5,5	<b>18</b>	<b>18</b>	<b>27</b>	Z19/18x18x27
	6,8	10	16	11	6,6	<b>20</b>	<b>22</b>	<b>36</b>	20x22x36
8	9	11	24	15	9	<b>25</b>	<b>30</b>	<b>46</b>	25x30x46
10	11	16	30	18	11	<b>32</b>	<b>32</b>	<b>56</b>	32x32x56
12						<b>35</b>	<b>35</b>		35x35x56
15	13	17	40	20	13,5	<b>40</b>	<b>50</b>	<b>76</b>	40x50x76
		20	50			<b>45</b>	<b>65</b>		<b>86</b>

# Z 190 /...


Führungsbacke, DLC  
 Guide jaw, DLC  
 Plot pour logement de guidage plat, DLC

Mat.: 1.2162

DLC beschichtet / with DLC coating / avec revêtement DLC

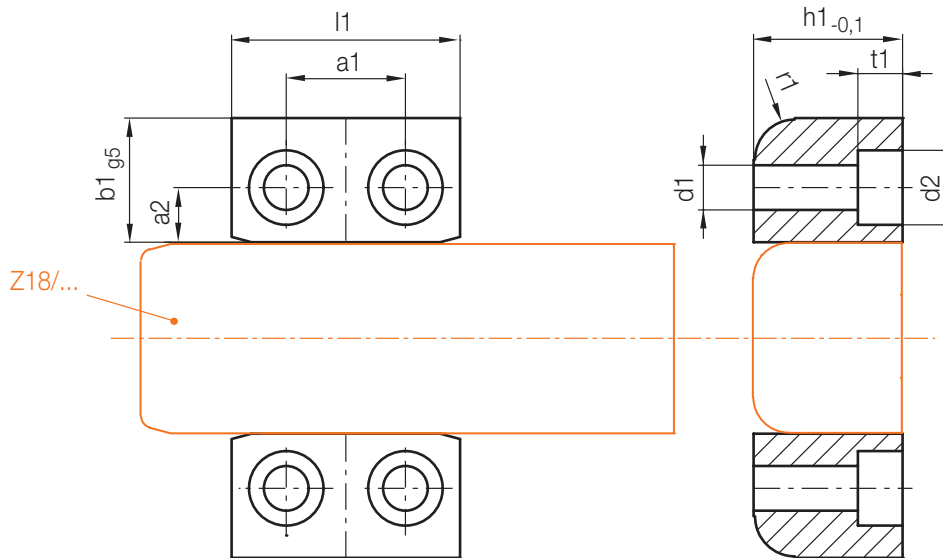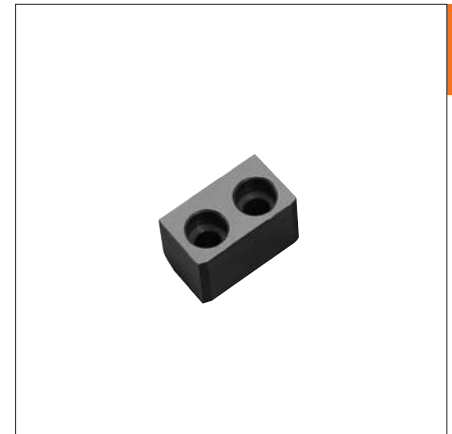

Z18/...

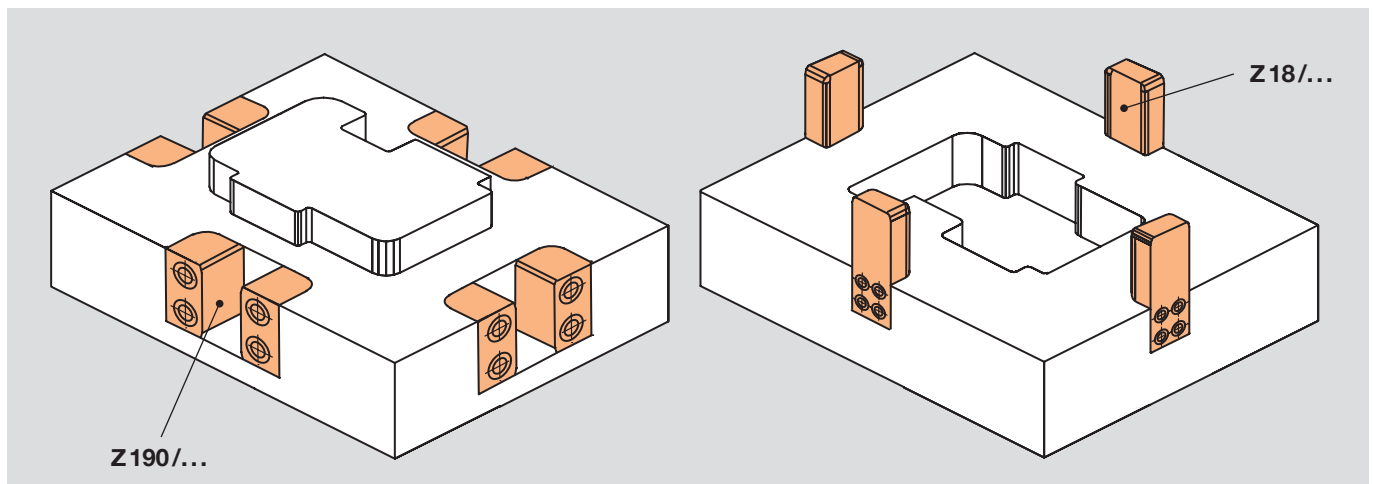

Z190/...

Z18/...

r1	t1	a2	a1	d2	d1	b1	h1	l1	Nr. / No.
6	5,7	8	12	10	5,5	18	18	27	Z190/18x18x27
	6,8	10	16	11	6,6	20	22	36	20x22x36
8	9	11	24	15	9	25	30	46	25x30x46
10	11	16	30	18	11	32	32	56	32x32x56
12		35	35	56	35x35x56				
15	13	17	40	20	13,5	40	50	76	40x50x76
		20	50	76	45	65	86	45x65x86	