




Z 185 /...

Führungsleiste
Guide strip
Barre de guidage



Mat.: 1.2842/58 + 2 HRC

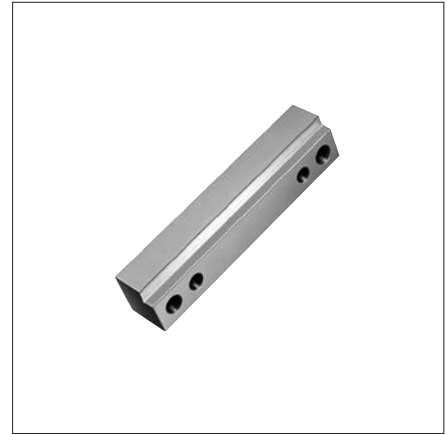

Typ 2

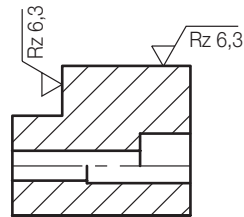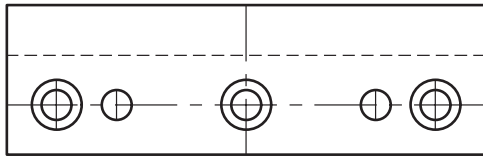

Typ 1

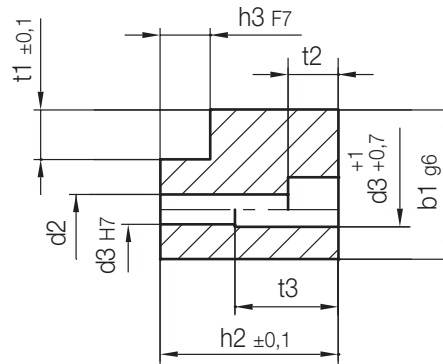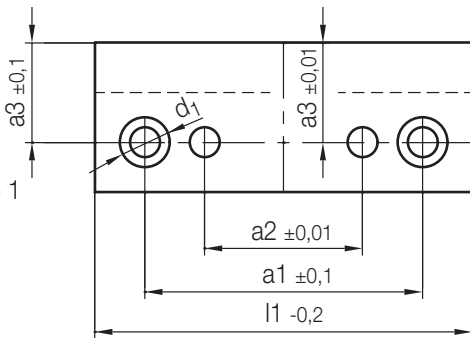


Typ	h3	h2	t3	t2	t1	a3	a2	a1	d3	d2	d1	b1	Z 180/... h1	l1	Nr./No.
1	4	11	3,5	5,7	5	9,5	14	34	5	5,5	10	16	12	50	Z 185 / 16x12x 50
							35	55							71
2							54	74							90
1	5	19	9,5	6,8		12	40	64	6	6,6	11	20	20	80	Z 185 / 20x20x 80
							60	84							100
2							85	109							125
1	6	31	19	9	6	15,5	50	80	8	9	15	25	32	100	Z 185 / 25x32x 100
							75	105							125
2							110	140							160
1	8	49	34	11	7	18	55	95	10	11	18	30	50	125	Z 185 / 30x50x 125
							90	130							160
2							130	170							200



Z 185 W/...

Führungsleiste, selbstschmierend
 Guide strip, self lubricating
 Barre de guidage, autolubrifiante



Mat.: 2.0492/180 HB
 max. °C: 200

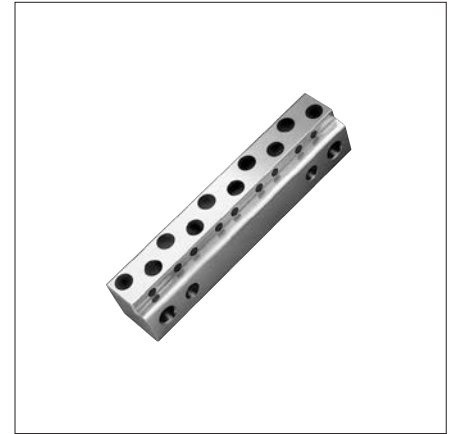

Typ 2

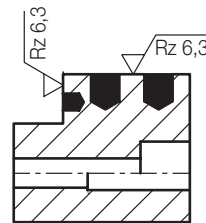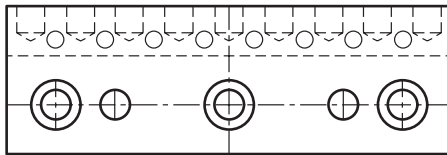

Typ 1

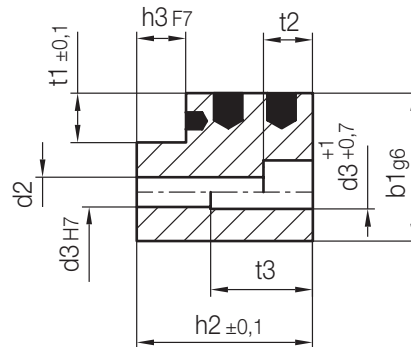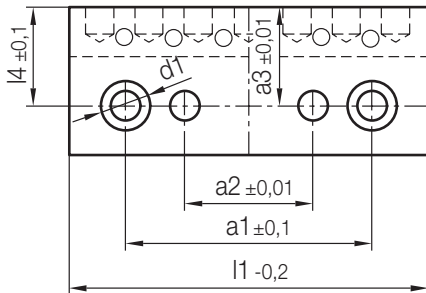

Typ	h3	h2	t3	t2	t1	a3	a2	a1	d3	d2	d1	b1	Z180/... h1	l1	Nr./No.
1	4	11	-	5,7	5	9,5	14	34	5	5,5	10	16	12	50	Z 185W/16x12x 50
							35	55						71	71
2							54	74						90	90
1	5	19	9,5	6,8		12	40	64	6	6,6	11	20	20	80	Z 185W/20x20x 80
							60	84						100	100
2							85	109						125	125
1	6	31	19	9	6	15,5	50	80	8	9	15	25	32	100	Z 185W/25x32x100
							75	105						125	125
2							110	140						160	160
1	8	49	34	11	7	18	55	95	10	11	18	30	50	125	Z 185W/30x50x125
							90	130						160	160
2							130	170						200	200

