



Z2302 /...

Verriegelungszyylinder
Positive locking cylinder
Cylindre de verrouillage

max. °C: 180

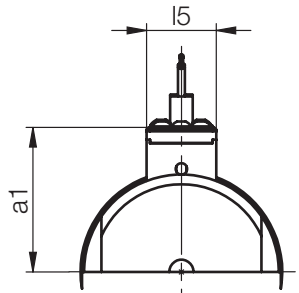

Ansicht/ View/ Vue "X"

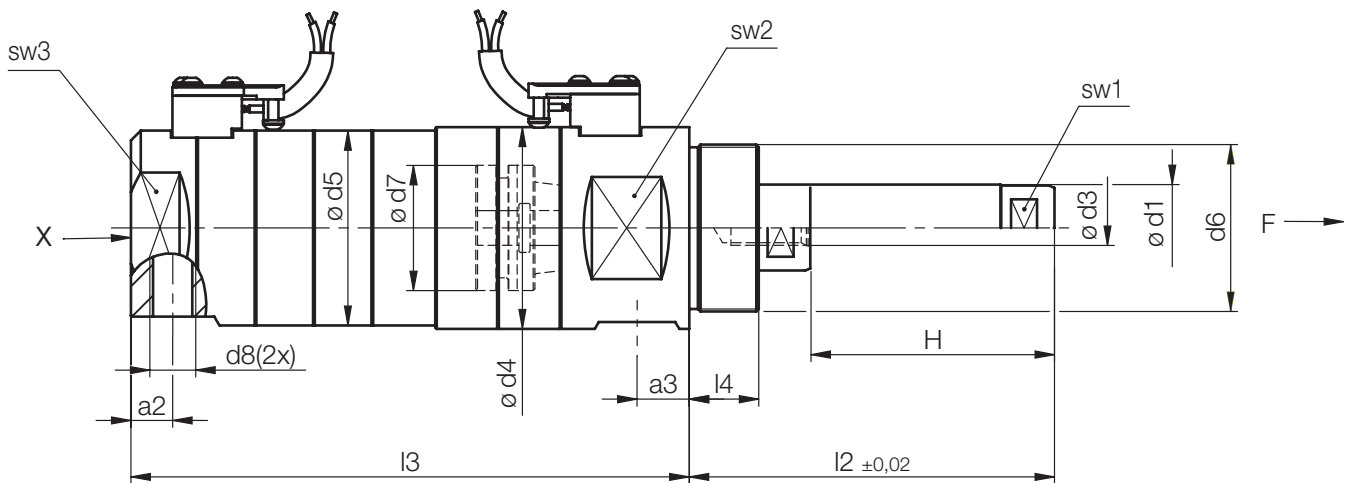

F [kN]	sw3	sw2	sw1	a3	a2	a1	l5	l4	l3	l2	d8	d7	d6	d5	d4	d3	d1	H	Nr./No.
60	32	32	12	12	8,4	32	18	15	90	45	G1/8	24	M30x1,5	37	38	M8	16	20	Z 2302 / 16 x 20
									110	65							40	40	
100	41	41	14	14	11	37	20	18	115	60	G1/4	30	M40x1,5	47	49		20	30	Z 2302 / 20 x 30
									145	90							60	60	
130	46	50	18	15	12	42	20	20	125,5	70		36	M48x1,5	56	58	M10	25	35	Z 2302 / 25 x 35
									160,5	105							70	70	
200	60	60	24	20	13	49	25	25	155	90		45	M60x1,5	69	72	M12	32	45	Z 2302 / 32 x 45
									200	135							90	90	
280	75	75	32	24	14	57	32	32	184,5	105	G3/8	56	M75x1,5	84	89	M16	42	50	Z 2302 / 42 x 50
									235	155							100	100	
500	90	95	41	26	17	65	42	42	216	130		71	M95x2	104	112		50	60	Z 2302 / 50 x 60
									276	190							120	120	
700	105	110	50	36	19	71	50	50	260	155	G1/2	84	M110x2	119	129	M20	60	75	Z 2302 / 60 x 75
									335	230							150	150	