


## Z2702/...

T-Verschraubung  
T-pipe connector  
Raccord fileté en T

Mat.: St37  
DIN EN ISO 8434-1 (DIN 2353)

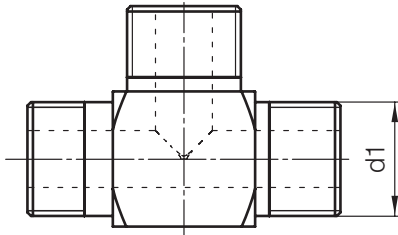


Typ	d1	Nr./No.
T06L	<b>M 12x1,5</b>	Z2702/12x1,5
T08L	<b>M 14x1,5</b>	14x1,5
T10L	<b>M 16x1,5</b>	16x1,5
T12L	<b>M 18x1,5</b>	18x1,5
T15L	<b>M 22x1,5</b>	22x1,5

## Z2703/...

T-Verschraubung, verstellbar  
T-pipe connector, adjustable  
Raccord fileté en T, réglable

Mat.: St37  
DIN EN ISO 8434-1 (DIN 2353)

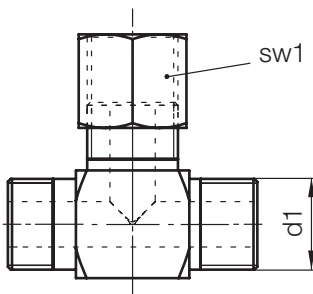

Typ	sw1	d1	Nr./No.
ET06L	14	<b>M 12x1,5</b>	Z2703/12x1,5
ET08L	17	<b>M 14x1,5</b>	14x1,5
ET10L	19	<b>M 16x1,5</b>	16x1,5
ET12L	22	<b>M 18x1,5</b>	18x1,5
ET15L	27	<b>M 22x1,5</b>	22x1,5

