


Z371/...

Federndes Druckstück, geschlitzt
Ball catch, threaded with screw driver slot
Vis à bille avec ressort, rainurée

Mat.: 1.4305
max. 250 °C

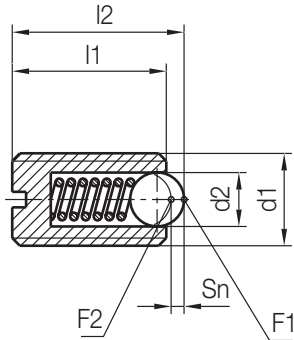


F2 [N]	F1 [N]	Sn	l2	d2	d1	l1	Nr./No.
11,6	6	0,64	9,8	2,5	M 4	9	Z371/ 4x 9
13,3	8,8	0,72	12,9	3	M 5	12	5x12
15,1	11,2	0,8	15	3,5	M 6	14	6x14
29,5	18,5	1,2	17,5	5	M 8	16	8x16
43	23,9	1,6	21	6	M10	19	10x19
59,8	35,9	2	24,5	8	M12	22	12x22
101,6	74	2,4	27,5	10	M16	24	16x24

Z372/...

Federndes Druckstück, geschlitzt, mit Druckbolzen
Ball catch, threaded with screw driver slot
Vis à bille avec ressort, rainurée, avec tige de pression

Mat.: 1.0718
max. 250 °C

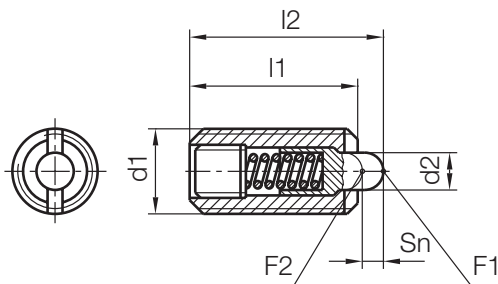

F2 [N]	F1 [N]	Sn	l2	d2	d1	l1	Nr./No.
2,8	1,7	0,8	13	1	M 3	12	Z372/ 3x12
12	5	1,2	16,5	1,5	M 4	15	4x15
16	7	1,8	20,3	2,4	M 5	18	5x18
		2	22,5	2,7	M 6	20	6x20
28	9	2,4	25	3,5	M 8	22	8x22
				4	M10		10x22
44	15	3,2	32	6	M12	28	12x28
80	45	4	37	7,5	M16	32	16x32
112	70	5,6	47	10	M20	40	20x40
144	80	8	62	12	M24	52	24x52