



Z491/...

Belüftungsventil, pneumatisch
Air valve, pneumatically activated
Soupape, pneumatique

Mat.: Ampcoloy 940
max. C°: 250

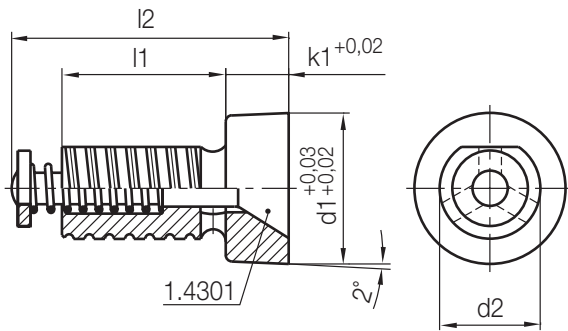


Typ 1

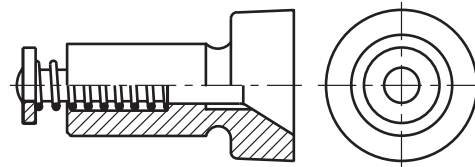

Typ 2

Z491/...

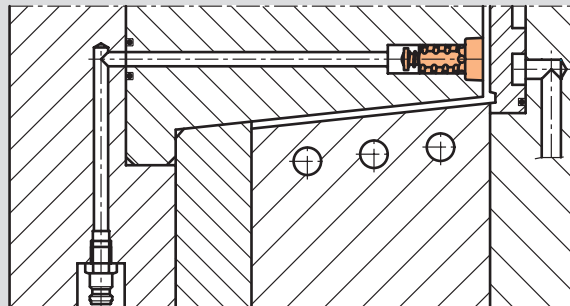

Typ	k1	l2	l1	d1	d2	Nr./No.
2	5	16	8	8	6	Z491/ 8x 6
1		21	13	12	8	12x 8
	6	22	12	16	10	16x10