
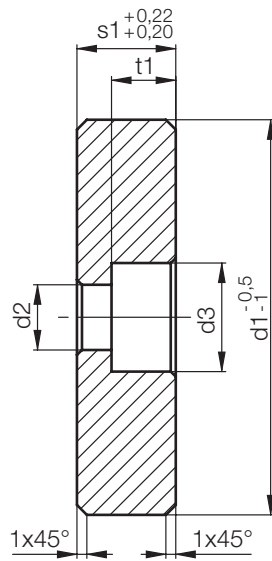


# Z555 /...

Abstimmplatte, rund  
 Adjustment plate, round  
 Plaque de pression, ronde

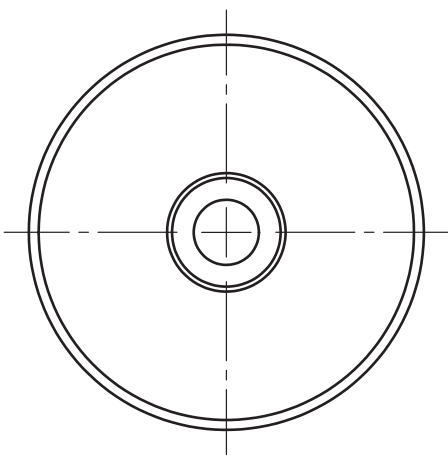


## Neu / New / Nouveau


t1	d3	d2	d1	s1	Nr./No.
5,5	10	5,5	32	8	Z555/32x 8
6,5	11	6,6		10	10
				12	12
5,5	10	5,5	40	8	Z555/40x 8
6,5	11	6,6		10	10
				12	12
			50	10	Z555/50x10
				12	12
			64	10	12
12	12				

# Z556 /...

Abstimmplatte, eckig  
 Adjustment plate, rectangular  
 Plaquette de pression, angulaire

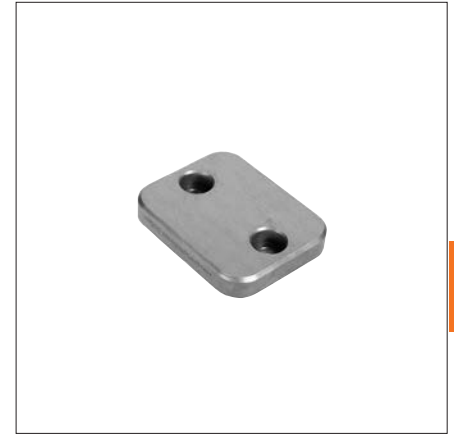

2

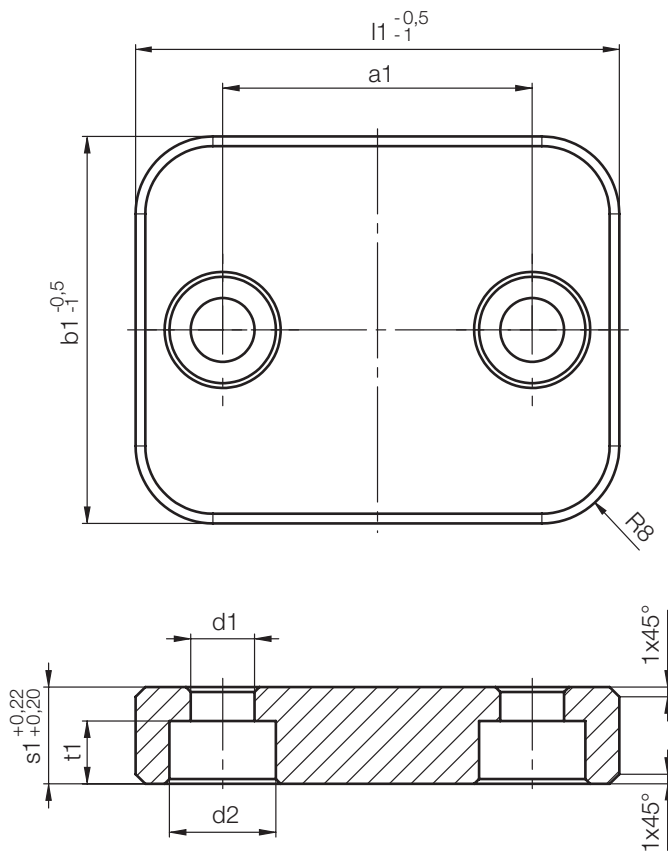


Neu / New / Nouveau

t1	a1	d2	d1	b1	l1	s1	Nr./No.
5,5	24	10	5,5	32	40	8	Z556/32x 40x 8
6,5		11	6,6			10	10
						12	12
5,5	40	10	5,5		64	8	64x 8
6,5		11	6,6			10	10
						12	12
5,5	64	10	5,5		100	8	100x 8
6,5		11	6,6			10	10
						12	12
5,5	32	10	5,5	40	50	8	Z556/40x 50x 8
6,5		11	6,6			10	10
						12	12
5,5	52	10	5,5		80	8	80x 8
6,5		11	6,6			10	10
						12	12
5,5	64	10	5,5		100	8	100x 8
6,5		11	6,6			10	10
						12	12

t1	a1	d2	d1	b1	l1	s1	Nr./No.
6,5	40	11	6,6	50	64	10	Z556/50x 64x 10
						12	12
						100	10
	64				12	12	
	80				125	10	125x 10
					12	12	
	52			64	80	10	Z556/64x 80x 10
						12	12
	64					100	10
					12	12	
	80				125	10	125x 10
					12	12	
	100				160	10	160x 10
					12	12	

# Z557/...

Abstimmplatte, eckig mit Schmiernuten  
 Adjustment plate, rectangular with lubrication grooves  
 Plaquette de pression, angulaire, avec rainures de graissage

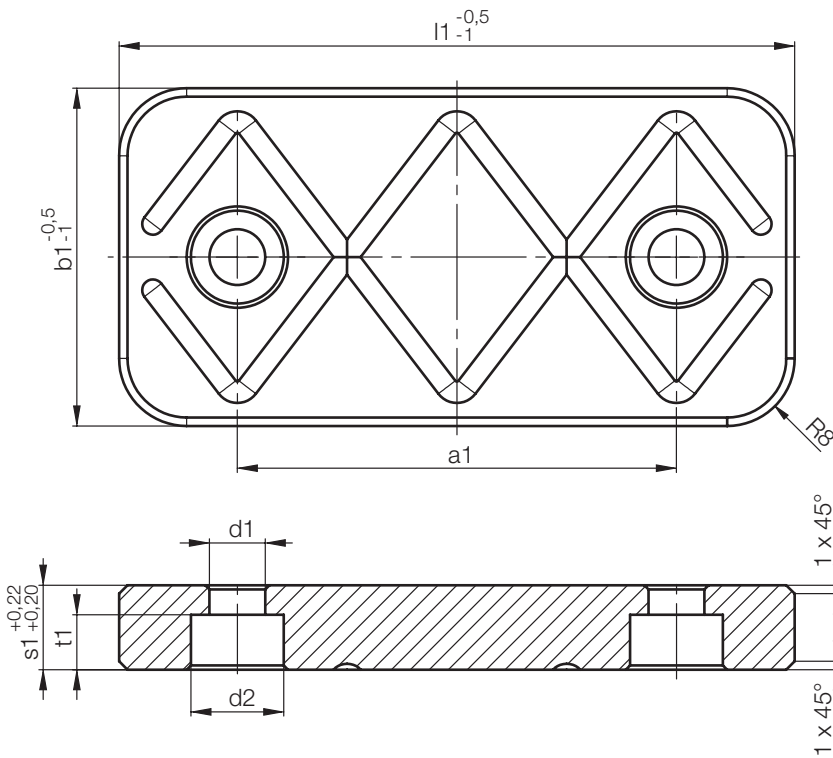


Neu / New / Nouveau

t1	a1	d2	d1	b1	l1	s1	Nr./No.
5,5	24	10	5,5	32	40	8	Z557/32x 40x 8
6,5		11	6,6			10	10
						12	12
5,5	40	10	5,5		64	8	64x 8
6,5		11	6,6			10	10
						12	12
5,5	64	10	5,5		100	8	100x 8
6,5		11	6,6			10	10
						12	12
5,5	32	10	5,5	40	50	8	Z557/40x 50x 8
6,5		11	6,6			10	10
						12	12
5,5	52	10	5,5		80	8	80x 8
6,5		11	6,6			10	10
						12	12
5,5	64	10	5,5		100	8	100x 8
6,5		11	6,6			10	10
						12	12

t1	a1	d2	d1	b1	l1	s1	Nr./No.	
6,5	40	11	6,6	50	64	10	Z557/50x 64x10	
						12	12	
						100	10	100x10
	64					12	12	
	80					125	10	125x10
						12	12	12
	52			64	80	10	Z557/64x 80x10	
						12	12	
	64					100	10	100x10
						12	12	12
	80					125	10	125x10
						12	12	12
	100					160	10	160x10
						12	12	12

Z555/...  
Z556/...

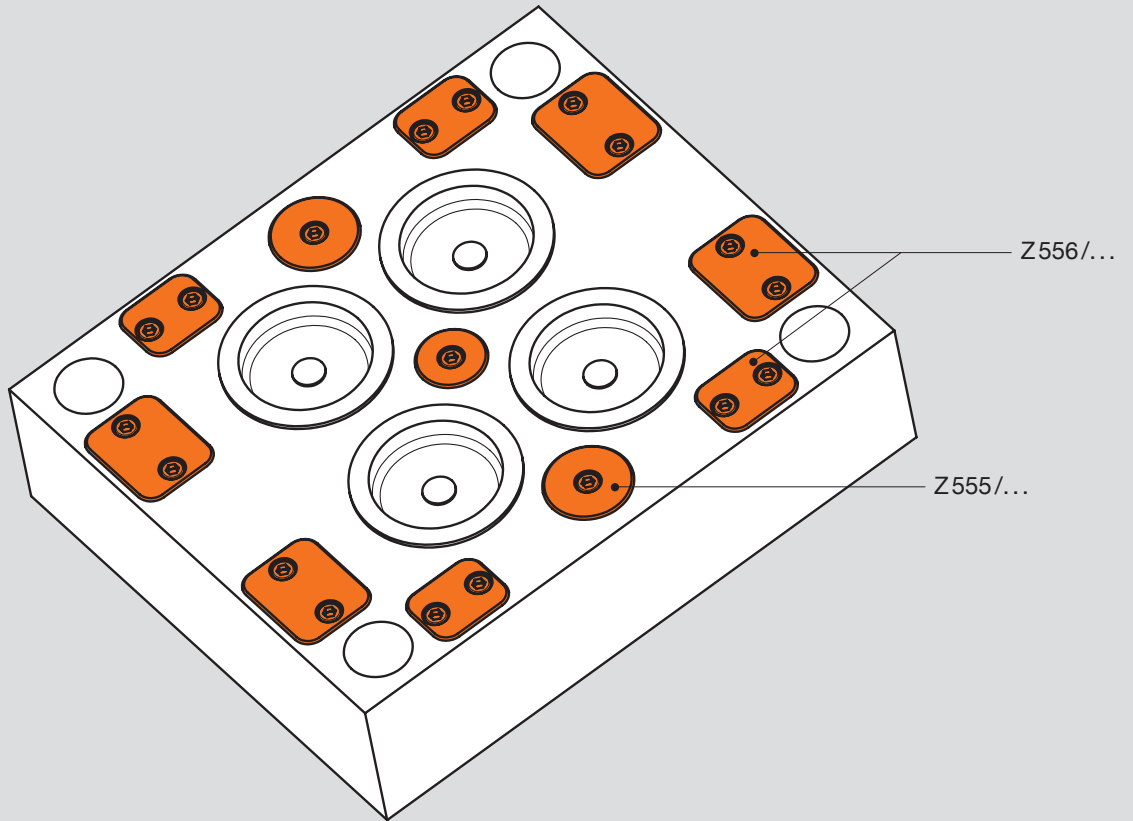

Z556/...  
Z557/...

