


# Z630/...


Elastomer Druckfeder, leicht  
Elastomer-compression spring, soft  
Ressort de compression en élastomère, faible

Kennfarbe: rot  
Colour code: red  
Couleur distinctive: rouge

Mat.: PUR/80 Shore A  
DIN ISO 10069-1

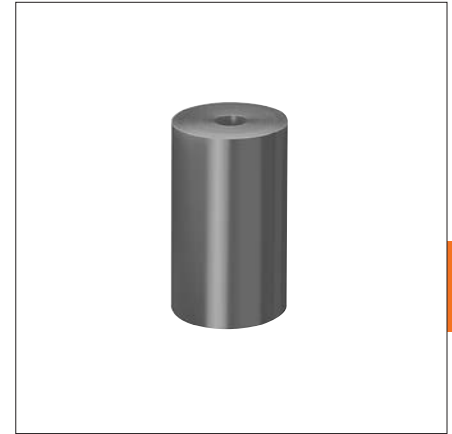

2

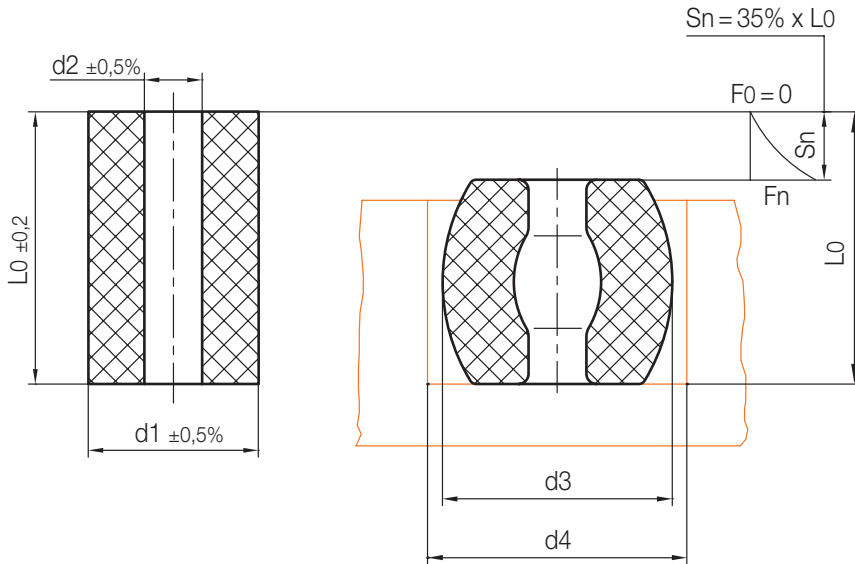



F <sub>n</sub>	S <sub>n</sub>	d <sub>4</sub>	d <sub>3</sub>	d <sub>2</sub>	d <sub>1</sub>	L <sub>0</sub>	Nr./No.	F <sub>n</sub>	S <sub>n</sub>	d <sub>4</sub>	d <sub>3</sub>	d <sub>2</sub>	d <sub>1</sub>	L <sub>0</sub>	Nr./No.
940	4,2	26	22	6,5	16	12	Z630/16x12	10400	8,7	75	68	17	50	25	Z630/ 50x 25
900	5,6					16	16	9970	11,2					32	32
880	7					20	20	9650	14					40	40
860	8,7					25	25	9400	17,5					50	50
830	11,2					32	32	9140	22					63	63
1440	4,2					32	27	8,5	20					12	Z630/20x12
1400	5,8	16	16	17600	11,2					32	Z630/ 63x 32				
1350	7	20	20	16880	14					40	40				
1330	8,7	25	25	16300	17,5					50	50				
1280	11,2	32	32	15770	22					63	63				
1260	14	40	40	15260	28					80	80				
2270	5,6	38	34	10,5	25	16	Z630/25x16	14940	35	118	108	21	80	100	100
2200	7					20	20	28690	14					40	Z630/ 80x 40
2160	8,7					25	25	27500	17,5					50	50
2090	11,2					32	32	26400	22					63	63
2050	14					40	40	25500	28					80	80
1980	17,5					50	50	24900	35					100	100
3850	5,6	48	43	13,5	32	16	Z630/32x16	24200	43,7	150	135	100	100	125	125
3740	7					20	20	46700	17,5					50	Z630/100x 50
3600	8,7					25	25	44500	22					63	63
3440	11,2					32	32	42700	28					80	80
3420	14					40	40	41500	35					100	100
3350	17,5					50	50	40000	43,7					125	125
6660	7	61	54	13,5	40	20	Z630/40x20	73900	22	188	169	27	125	63	Z630/125x 63
6410	8,7					25	25	69500	28					80	80
6190	11,2					32	32	66100	35					100	100
6010	14					40	40	64800	43,7					125	125
5870	17,5					50	50	62300	56					160	160
5760	22					63	63								

# Z631/...

Elastomer Druckfeder, mittel  
 Elastomer-compression spring, medium  
 Ressort de compression en élastomère, moyenne

Kennfarbe: grün  
 Colour code: green  
 Couleur distinctive: verte

Mat.: PUR/90 Shore A  
 DIN ISO 10069-1

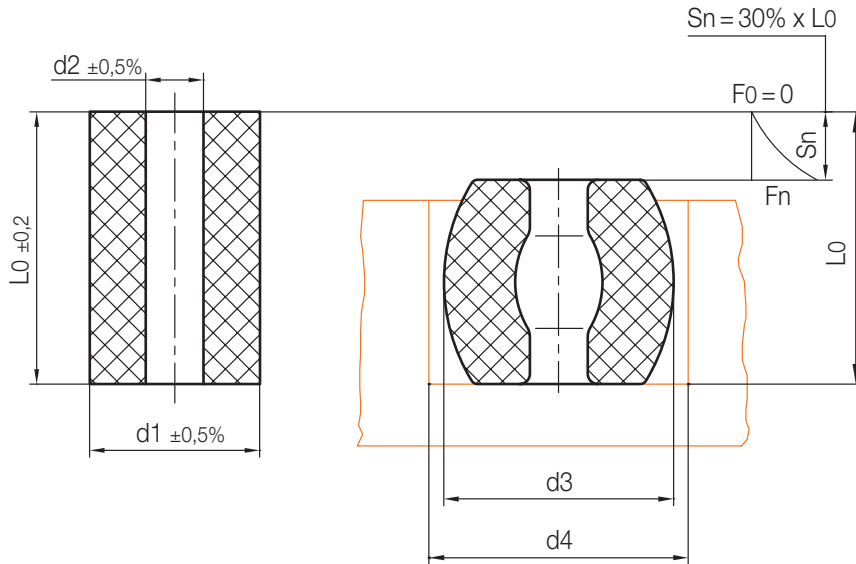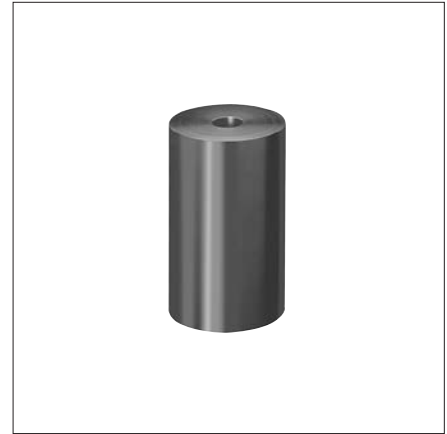

Fn	Sn	d4	d3	d2	d1	L0	Nr./No.
1790	3,6	26	21	6,5	16	12	Z 631/ 16x12
1730	4,8					16	16
1690	6					20	20
1660	7,5					25	25
1590	9,6					32	32
2760	3,6	32	26	8,5	20	12	Z 631/ 20x12
2690	4,8					16	16
2590	6					20	20
2550	7,5					25	25
2450	9,6					32	32
2420	12	40	40				
4350	4,8	37	33	10,5	25	16	Z 631/ 25x16
4210	6					20	20
4140	7,5					25	25
4000	9,6					32	32
3930	12					40	40
3800	15	50	50				
7380	4,8	47	42	13,5	32	16	Z 631/ 32x16
7180	6					20	20
6900	7,5					25	25
6620	9,6					32	32
6560	12					40	40
6420	15	50	50				
12770	6	59	52		40	20	Z 631/ 40x20
12280	7,5					25	25
11870	9,6					32	32
11520	12					40	40
11250	15					50	50
11040	18,9	63	63				


Fn	Sn	d4	d3	d2	d1	L0	Nr./No.
19940	7,5	72	65	17	50	25	Z 631/ 50x 25
19110	9,6					32	32
18500	12					40	40
18000	15					50	50
17530	18,9					63	63
17220	24	80	80				
33740	9,6	91	82		63	32	Z 631/ 63x 32
32360	12					40	40
31260	15					50	50
30220	18,9					63	63
29260	24					80	80
28640	30	100	100				
55000	12	114	104	21	80	40	Z 631/ 80x 40
52700	15					50	50
50600	18,9					63	63
49000	24					80	80
47700	30					100	100
46400	37,5	125	125				
89500	15	145	130		100	50	Z 631/ 100x 50
85400	18,9					63	63
82000	24					80	80
79600	30					100	100
76600	37,5					125	125
142000	18,9	182	163	27	125	63	Z 631/ 125x 63
133000	24					80	80
127000	30					100	100
124000	37,5					125	125
119000	48					160	160

# Z632/...


Elastomer Druckfeder, stark  
 Elastomer-compression spring, hard  
 Ressort de compression en élastomère, forte

Kennfarbe: hellbraun  
 Colour code: light brown  
 Couleur distinctive: clair

Mat.: PUR/96 Shore A  
 DIN ISO 10069-1

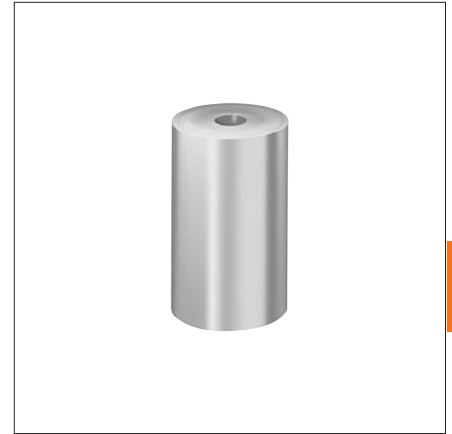

2

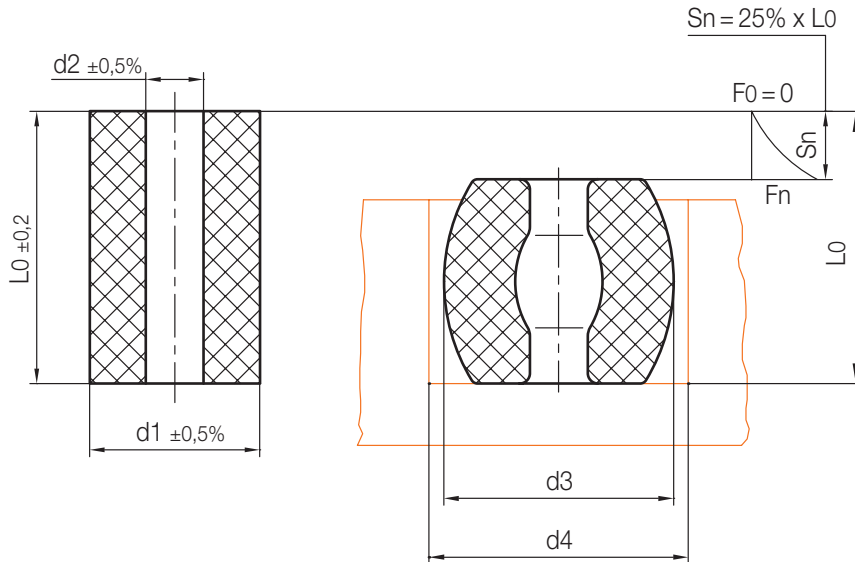

F <sub>n</sub>	S <sub>n</sub>	d <sub>4</sub>	d <sub>3</sub>	d <sub>2</sub>	d <sub>1</sub>	L <sub>0</sub>	Nr./No.
2260	3	26	20	6,5	16	12	Z632/16x12
2150	4					16	16
2130	5					20	20
2080	6,2					25	25
2000	8					32	32
3470	3	32	25	8,5	20	12	Z632/20x12
3390	4					16	16
3260	5					20	20
3210	6,2					25	25
3080	8					32	32
3040	10					40	40
5470	4	36	31	10,5	25	16	Z632/25x16
5290	5					20	20
5210	6,2					25	25
5030	8					32	32
4950	10					40	40
4770	12,5	50	50				
9290	4	47	40	13,5	32	16	Z632/32x16
9030	5					20	20
8680	6,2					25	25
8330	8					32	32
8250	10					40	40
8070	12,5	50	50				
16060	5	57	50		40	20	Z632/40x20
15450	6,2					25	25
14930	8					32	32
14500	10					40	40
14150	12,5					50	50
13890	15,7	63	63				

F <sub>n</sub>	S <sub>n</sub>	d <sub>4</sub>	d <sub>3</sub>	d <sub>2</sub>	d <sub>1</sub>	L <sub>0</sub>	Nr./No.
25090	6,2	69	62	17	50	25	Z632/ 50x 25
24040	8					32	32
23260	10					40	40
22650	12,5					50	50
22050	15,7					63	63
21660	20	80	80				
42450	8	84	78		63	32	Z632/ 63x 32
40700	10					40	40
39300	12,5					50	50
38020	15,7					63	63
36800	20					80	80
36020	25	100	100				
69180	10	109	99	21	80	40	Z632/ 80x 40
66300	12,5					50	50
63700	15,7					63	63
61600	20					80	80
60000	25					100	100
58300	31,2	125	125				
112600	12,5	139	124		100	50	Z632/100x 50
107400	15,7					63	63
103000	20					80	80
100000	25					100	100
96300	31,2					125	125
178000	15,7	174	155	27	125	63	Z632/125x 63
167000	20					80	80
159000	25					100	100
156000	31,2					125	125
150000	40					160	160