


Z635/...

Distanzrohr
 Spacer tube
 Tube d'entretoise

Mat.: $\approx 1.0711/40 + 10 \text{ HRC}$

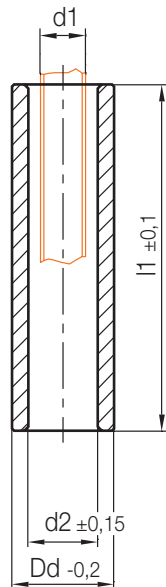

| Dd | d2 | d1 | l1 | Nr./No. |
|------|------|-------------|-----|-------------|
| 10 | 7 | M 6 | 40 | Z635/ 6x 40 |
| | | | 50 | 50 |
| | | | 63 | 63 |
| | | | 80 | 80 |
| 12,5 | 9 | M 8 | 50 | Z635/ 8x 50 |
| | | | 63 | 63 |
| | | | 80 | 80 |
| | | | 100 | 100 |
| 15 | 10,6 | M 10 | 50 | Z635/10x 50 |
| | | | 63 | 63 |
| | | | 80 | 80 |
| | | | 100 | 100 |
| | | | 125 | 125 |

| Dd | d2 | d1 | l1 | Nr./No. |
|----|------|-------------|-----|-------------|
| 15 | 10,6 | M 10 | 200 | Z635/10x200 |
| 20 | 13 | M 12 | 50 | Z635/12x 50 |
| | | | 63 | 63 |
| | | | 80 | 80 |
| | | | 100 | 100 |
| 25 | 17 | M 16 | 125 | 125 |
| | | | 200 | 200 |
| | | | 50 | Z635/16x 50 |
| | | | 63 | 63 |
| | | | 80 | 80 |
| | | | 100 | 100 |
| | | | 125 | 125 |
| | | | 200 | 200 |