


Z803 /...

Adapterkupplung, mit Absperrventil
 Adapter coupling, with valve
 Coupleur adaptateur, avec vanne d'arrêt

Mat.: 2.0401

Z802/...
 Z81/...
 Z811/...
 Z83/...
 Z830/...
 Z831/...
 Z90/...

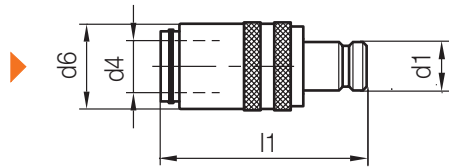

Z80/...
 Z801/...
 Z805/...
 Z8051/...
 Z807/...
 Z80700/...
 Z808/...
 Z82/...



Medium	max. C°
Luft/air/air	200
Öl/oil/huile	200
Wasser/water/eau	150



Schlauchgrenzwerte können abweichen!
 Hose limits can differ!
 Les valeurs limites des tuyaux peuvent différer!




p [bar]	l1	d6	d4	d1	Nr./No.
25	40,55	17,25	9	9,4 (USA)	Z803/ 9 x 9,4
	43	17,5	9,4 (USA)	9	9,4 x 9
	52,05	22,1	13	13,5 (USA)	13 x 13,5
	55,55	23	13,5 (USA)	13	13,5 x 13

Z804 /...

Adapterkupplung, mit freiem Durchgang
 Adapter coupling, open flow
 Coupleur adaptateur, à passage ouvert

Mat.: 2.0401

Z802/...
 Z81/...
 Z811/...
 Z83/...
 Z830/...
 Z831/...
 Z90/...

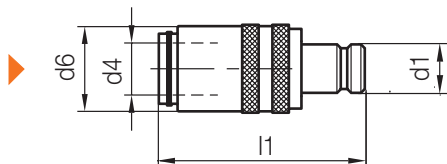

Z80/...
 Z801/...
 Z805/...
 Z8051/...
 Z807/...
 Z80700/...
 Z808/...
 Z82/...



Medium	max. C°
Luft/air/air	200
Öl/oil/huile	200
Wasser/water/eau	150



Schlauchgrenzwerte können abweichen!
 Hose limits can differ!
 Les valeurs limites des tuyaux peuvent différer!



p [bar]	l1	d6	d4	d1	Nr./No.
25	40,55	17,25	9	9,4 (USA)	Z804/ 9 x 9,4
	43	17,5	9,4 (USA)	9	9,4 x 9
	52,05	22,1	13	13,5 (USA)	13 x 13,5
	55,55	23	13,5 (USA)	13	13,5 x 13