


# Z803 /...

Adapterkupplung, mit Absperrventil  
 Adapter coupling, with valve  
 Coupleur adaptateur, avec vanne d'arrêt

Mat.: 2.0401

Z802/...  
 Z81/...  
 Z811/...  
 Z83/...  
 Z830/...  
 Z831/...  
 Z90/...

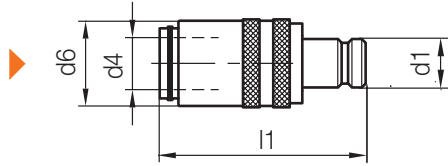

Z80/...  
 Z801/...  
 Z805/...  
 Z8051/...  
 Z807/...  
 Z80700/...  
 Z808/...  
 Z82/...



Medium	max. C°
Luft/air/air	200
Öl/oil/huile	120
Wasser/water/eau	100



Schlauchgrenzwerte können abweichen!  
 Hose limits can differ!  
 Les valeurs limites des tuyaux peuvent différer!




p [bar]	l1	d6	d4	d1	Nr./No.
25	40,55	17,25	9	9,4 (USA)	Z803/ 9 x 9,4
	43	17,5	9,4 (USA)	9	9,4 x 9
	52,05	22,1	13	13,5 (USA)	13 x 13,5
	55,55	23	13,5 (USA)	13	13,5 x 13

# Z804 /...

Adapterkupplung, mit freiem Durchgang  
 Adapter coupling, open flow  
 Coupleur adaptateur, à passage ouvert

Mat.: 2.0401

Z802/...  
 Z81/...  
 Z811/...  
 Z83/...  
 Z830/...  
 Z831/...  
 Z90/...

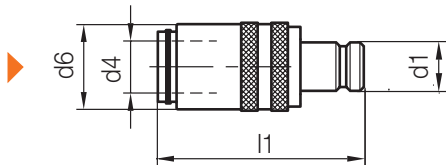

Z80/...  
 Z801/...  
 Z805/...  
 Z8051/...  
 Z807/...  
 Z80700/...  
 Z808/...  
 Z82/...



Medium	max. C°
Luft/air/air	200
Öl/oil/huile	120
Wasser/water/eau	100



Schlauchgrenzwerte können abweichen!  
 Hose limits can differ!  
 Les valeurs limites des tuyaux peuvent différer!



p [bar]	l1	d6	d4	d1	Nr./No.
25	40,55	17,25	9	9,4 (USA)	Z804/ 9 x 9,4
	43	17,5	9,4 (USA)	9	9,4 x 9
	52,05	22,1	13	13,5 (USA)	13 x 13,5
	55,55	23	13,5 (USA)	13	13,5 x 13