


# Z80PL /...

Schnellverschlusskupplung, mit Absperrventil  
 Shut-off coupling, with valve  
 Coupleur rapide, avec vanne d'arrêt

Mat.: 2.0401

Z802/..., Z8021/...  
 Z803/...  
 Z804/...  
 Z810/...  
 Z81/...  
 Z811/...  
 Z83/...  
 Z830/...  
 Z831/...  
 Z835/...  
 Z90/...  
 Z900/...

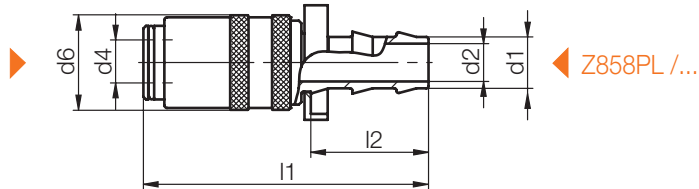

Medium	max. C°
Luft /air/air	200
Öl/oil/huile	200
Wasser / water / eau	150



Schlauchgrenzwerte können abweichen!  
 Hose limits can differ!  
 Les valeurs limites des tuyaux peuvent différer!




p [bar]	l2	l1	d6	d4	d2	d1	Nr./No.
25	22,4	54,2	17	9	6	9	Z80PL/ 9
	26,1	64,4	22	13	9	13	13

# Z80PL /...x45

Schnellverschlusskupplung, mit Absperrventil, 45° abgewinkelt  
 Shut-off coupling, with valve, 45° angled  
 Coupleur rapide, avec vanne d'arrêt, coudé à 45°

Mat.: 2.0401

Z802/..., Z8021/...  
 Z803/...  
 Z804/...  
 Z810/...  
 Z81/...  
 Z811/...  
 Z83/...  
 Z830/...  
 Z831/...  
 Z835/...  
 Z90/...  
 Z900/...

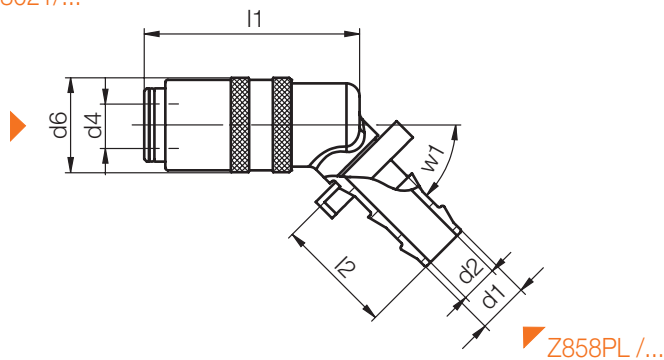

Medium	max. C°
Luft /air/air	200
Öl/oil/huile	200
Wasser / water / eau	150



Schlauchgrenzwerte können abweichen!  
 Hose limits can differ!  
 Les valeurs limites des tuyaux peuvent différer!




p [bar]	l2	l1	d6	d4	d2	d1	w1	Nr./No.
25	22,4	41	17	9	6	9	45°	Z80PL/ 9x45
	26,1	51	22	13	9	13		13


# Z80PL /...x90

Schnellverschlusskupplung, mit Absperrventil, 90° abgewinkelt  
 Shut-off coupling, with valve, 90° angled  
 Coupleur rapide, avec vanne d'arrêt, coudé à 90°

Mat.: 2.0401

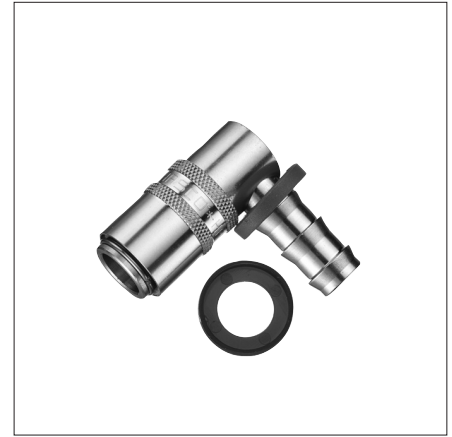

Z802/..., Z8021/...  
 Z803/...  
 Z804/...  
 Z810/...  
 Z81/...  
 Z811/...  
 Z83/...  
 Z830/...  
 Z831/...  
 Z835/...  
 Z90/...  
 Z900/...

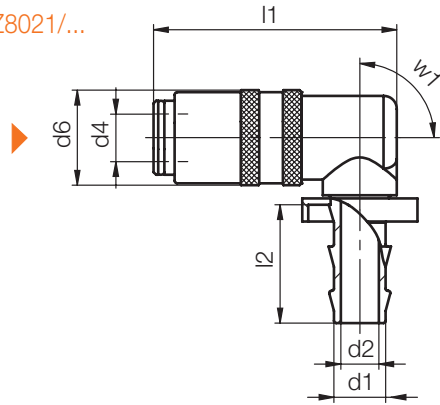

↑ Z858PL /...



Medium	max. C°
Luft /air/air	200
Öl/oil/huile	200
Wasser /water/eau	150



Schlauchgrenzwerte können abweichen!  
 Hose limits can differ!  
 Les valeurs limites des tuyaux peuvent différer!

p [bar]	l2	l1	d6	d4	d2	d1	w1	Nr./No.
25	22,4	46	17	9	6	<b>9</b>	<b>90°</b>	Z80PL/ 9x90
	26,1	56,5	22	13	9	<b>13</b>		13