


Z80PL /...

Schnellverschlusskupplung, mit Absperrventil
 Shut-off coupling, with valve
 Coupleur rapide, avec vanne d'arrêt

Mat.: 2.0401

Z802/..., Z8021/...
 Z803/...
 Z804/...
 Z810/...
 Z81/...
 Z811/...
 Z83/...
 Z830/...
 Z831/...
 Z835/...
 Z90/...
 Z900/...

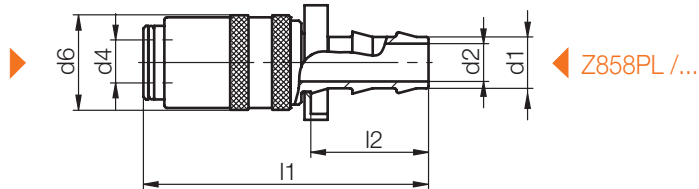

Medium	max. C°
Luft /air/air	200
Öl/oil/huile	120
Wasser / water / eau	100

⚠
 Schlauchgrenzwerte können abweichen!
 Hose limits can differ!
 Les valeurs limites des tuyaux peuvent différer!




p [bar]	l2	l1	d6	d4	d2	d1	Nr./No.
25	22,4	54,2	17	9	6	9	Z80PL/ 9
	26,1	64,4	22	13	9	13	13

Z80PL /...x45

Schnellverschlusskupplung, mit Absperrventil, 45° abgewinkelt
 Shut-off coupling, with valve, 45° angled
 Coupleur rapide, avec vanne d'arrêt, coudé à 45°

Mat.: 2.0401

Z802/..., Z8021/...
 Z803/...
 Z804/...
 Z810/...
 Z81/...
 Z811/...
 Z83/...
 Z830/...
 Z831/...
 Z835/...
 Z90/...
 Z900/...

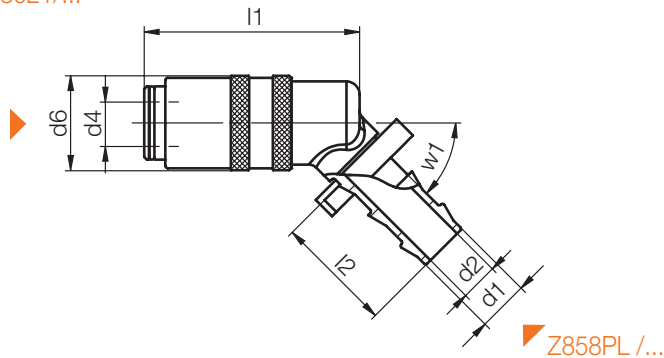

Medium	max. C°
Luft /air/air	200
Öl/oil/huile	120
Wasser / water / eau	100

⚠
 Schlauchgrenzwerte können abweichen!
 Hose limits can differ!
 Les valeurs limites des tuyaux peuvent différer!



p [bar]	l2	l1	d6	d4	d2	d1	w1	Nr./No.
25	22,4	41	17	9	6	9	45°	Z80PL/ 9x45
	26,1	51	22	13	9	13		13


Z80PL /...x90

Schnellverschlusskupplung, mit Absperrventil, 90° abgewinkelt
 Shut-off coupling, with valve, 90° angled
 Coupleur rapide, avec vanne d'arrêt, coudé à 90°

Mat.: 2.0401



- Z802/..., Z8021/...
- Z803/...
- Z804/...
- Z810/...
- Z81/...
- Z811/...
- Z83/...
- Z830/...
- Z831/...
- Z835/...
- Z90/...
- Z900/...

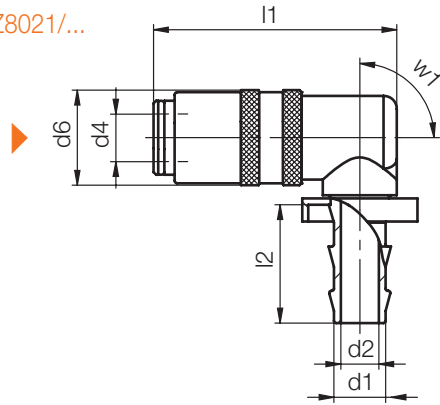

Z858PL /...



Medium	max. C°
Luft /air/air	200
Öl/oil/huile	120
Wasser /water/eau	100

!
 Schlauchgrenzwerte können abweichen!
 Hose limits can differ!
 Les valeurs limites des tuyaux peuvent différer!

p [bar]	l2	l1	d6	d4	d2	d1	w1	Nr./No.
25	22,4	46	17	9	6	9	90°	Z80PL/ 9x90
	26,1	56,5	22	13	9	13		13