


Z811/...

Verschlussnippel, mit Absperrventil
 Shut-off nipple, with valve
 Raccord rapide, avec vanne d'arrêt

Mat.: 2.0401

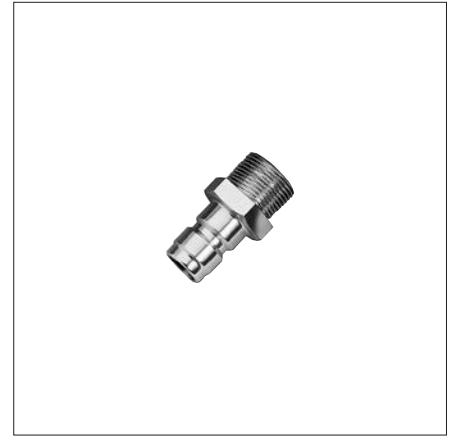


Medium	max. C°
Luft/air/air	200
Öl/oil/huile	120
Wasser/water/eau	100



Schlauchgrenzwerte können abweichen!
 Hose limits can differ!
 Les valeurs limites des tuyaux peuvent différer!

Mit Dichtmittel beschichtet
 Coated with sealing compound
 Recouvert avec ruban d'étanchéité

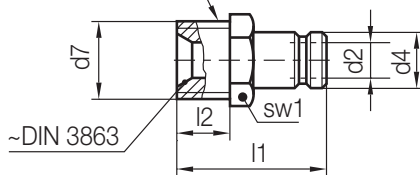

Z80/... Z80PL /...
 Z802/...
 Z807/...
 Z80700/...
 Z805/...
 Z82/...



p [bar]	sw1	l2	l1	d2	d4	d7	Nr./No.
25	9	5	28	2,7	5	M 5x0,5	Z811/ 5 x 5x0,5
		7	30			M 8x0,75	8x0,75
	15	12	29	6	9	M14x1,5	9 x 14x1,5
						G1/4A	G1/4
	17	12	30	9	13	M16x1,5	13 x 16x1,5
						G3/8A	G3/8
	27	16	51	13	19	M24x1,5	19 x 24x1,5
	22	12	47			G1/2A	G1/2
27	16	51	G3/4A			G3/4	