
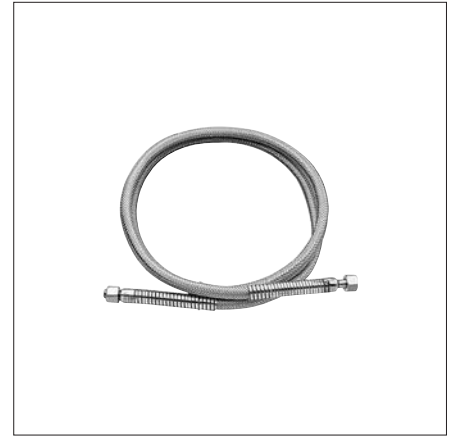


Z855 /...

Metallschlauch, mit Metallumflechtung
 Corrugated metal hose, with metal braiding
 Tuyau métallique flexible

Mat.: Metall

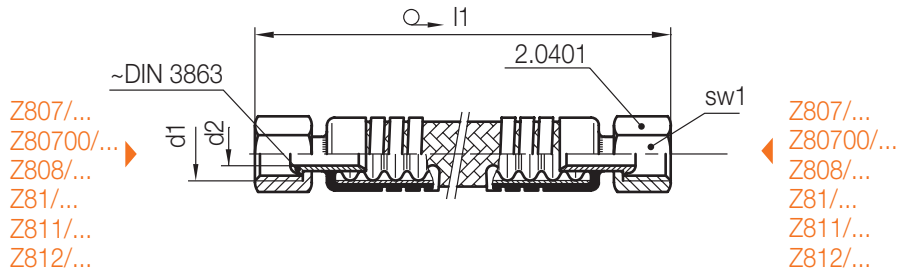


| Medium | max. C° |
|------------------|---------|
| Luft/air/air | 250 |
| Öl/oil/huile | 250 |
| Wasser/water/eau | 250 |

| p [bar] | sw1 | min. r | d2 | Typ | l1 | d1 | Nr./No. |
|---------|-----|--------|----|------|---------|----------------------|---------------------|
| 30 | 17 | 80 | 6 | 9 | 500 | M14x1,5 | Z855/ 9/ 500x14x1,5 |
| | | | | | 1000 | | 1000x14x1,5 |
| | | | | | 2000 | | 2000x14x1,5 |
| | 22 | 125 | 8 | 13 | 500 | M16x1,5 | Z855/13/ 500x16x1,5 |
| | | | | | 1000 | | 1000x16x1,5 |
| | | | | | 2000 | | 2000x16x1,5 |
| 30 | 140 | 12 | 19 | 1000 | M24x1,5 | Z855/19/ 1000x24x1,5 | |
| | | | | 2000 | | 2000x24x1,5 | |

Z86 /...

Schlauchschelle
 Hose clip
 Collier de serrage

DIN 3017-1

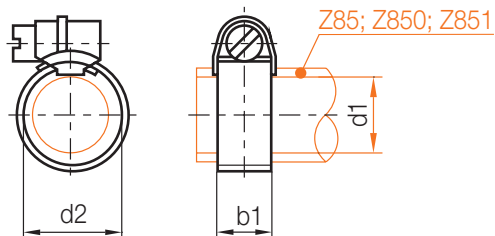

| b1 | min. d2 | max. d2 | d1 | Nr./No. |
|----|---------|---------|----|---------|
| 5 | 7 | 11 | 5 | Z86/ 5 |
| 9 | 10 | 16 | 9 | 9 |
| 12 | 12 | 20 | 13 | 13 |
| | 20 | 32 | 19 | 19 |