


Z93/...

Dichtband
Sealing tape
Ruban d'étanchéité

Mat.: PTFE
max. °C: 250
min. °C: -160

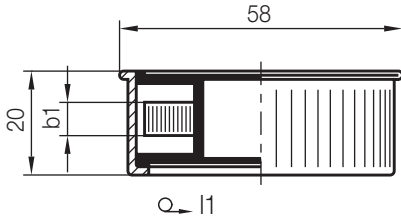


| l1 [m] | b1 | Nr./No. |
|--------|-----|--------------|
| 12 | 6,5 | Z93/ 12x 6,5 |
| | 13 | 12x13 |

Z94/...

Verschlusschraube, konisch
Hexagon socket pipe plug, conical
Bouchon, conique

Mat.: 2.0401
DIN 906

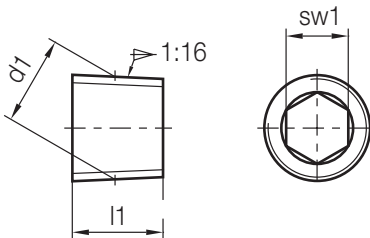

| | sw1 | l1 | d1 | Nr./No. |
|----|-----|----|-----------------|------------|
| 10 | 3 | 5 | M 5x0,5 | Z94/ 5x0,5 |
| | | 8 | M 6x0,75 | 6x0,75 |
| | | | M 7x1 | 7x1 |
| | 4 | | M 8x0,75 | 8x0,75 |
| | 5 | | M 9x1 | 9x1 |
| | | | M10x1 | 10x1 |
| | | | M11x1 | 11x1 |
| | 6 | | | |

| | sw1 | l1 | d1 | Nr./No. |
|----|-----|----|-----------------|-------------|
| 10 | 6 | 8 | M 12x1,5 | Z94/ 12x1,5 |
| | | 7 | M 14x1,5 | 14x1,5 |
| | | 5 | R 1/8 | Z94/ R1/8 |
| | 7 | 10 | R 1/4 | R1/4 |
| | 8 | | R 3/8 | R3/8 |
| | 10 | | R 1/2 | R1/2 |
| | | | | |
| | | | | |
| | | | | |
| | | | | |