


# Z976/...

TempFlex,  
metrisch/metric/métrique

Mat.: 1.4404/2.0401



Z80/...  
Z80HT/... Z80PL /...  
Z801/... Z801PL /...  
Z802/... Z8021/...  
Z803/...  
Z804/...  
Z805/...  
Z8051/...  
Z807/...  
Z807HT/...  
Z80700/...  
Z80700HT/...  
Z808/...  
Z82/...

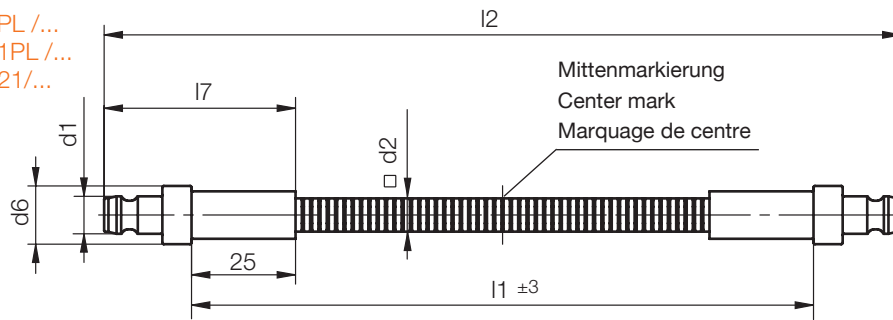


Z80/...  
Z80HT/... Z80PL /...  
Z801/... Z801PL /...  
Z802/... Z8021/...  
Z803/...  
Z804/...  
Z805/...  
Z8051/...  
Z807/...  
Z807HT/...  
Z80700/...  
Z80700HT/...  
Z808/...  
Z82/...

17	l2	d6	d1	d2	l1	Nr./No.
46	542	14	9	8	500	Z976/ 9x 8x 500
	792				750	750
	1042				1000	1000
	542	22	13	12	500	Z976/13x12x 500
	792				750	750
	1042				1000	1000

# Z977/...

TempFlex, US

Mat.: 1.4404/1.4301

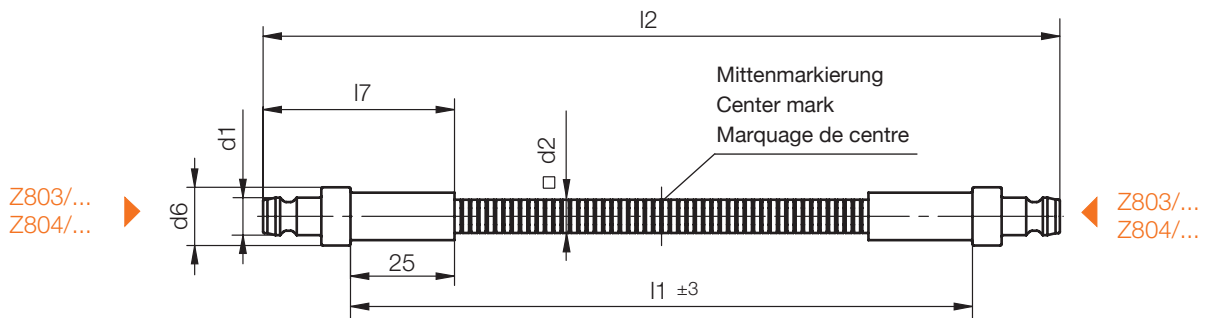

l2	d1	d2	l1	Nr./No.
542	9,4	8	500	Z977/9,4x8x 500
792			750	750
1042			1000	1000

Firma/Company/Société: \_\_\_\_\_

Zuständig/Contact/Responsable: \_\_\_\_\_


Tel.: \_\_\_\_\_ Fax: \_\_\_\_\_

E-mail: \_\_\_\_\_ Datum/Date: \_\_\_\_\_

Bestellung/Order/Commande Nr./No.: \_\_\_\_\_  Anfrage/Quotation/Demande

**Z976/.../S** TempFlex, metrisch/metric/métrique

**Z977/.../S** TempFlex, US

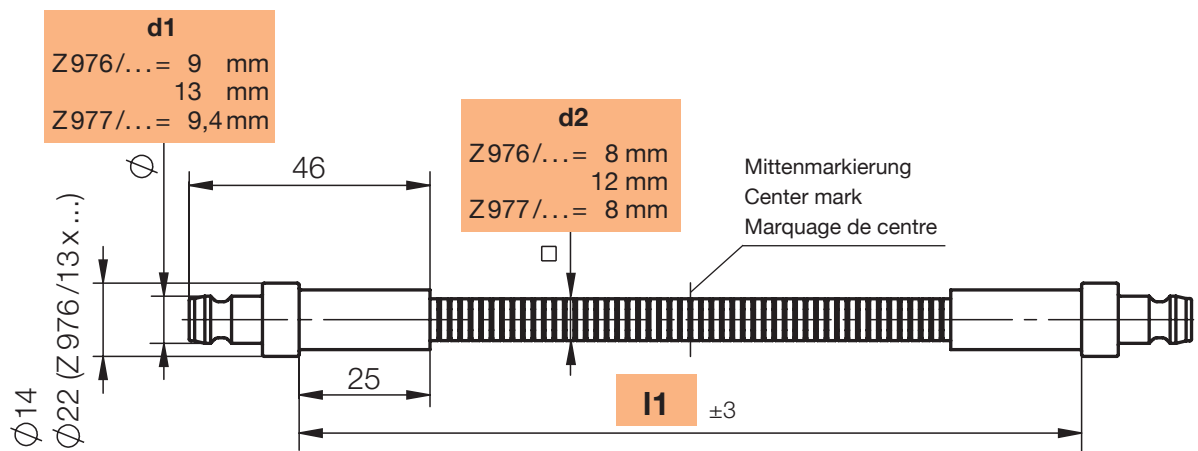

**Bestellbeispiele**  
**Order examples**  
**Exemples de commande**

Z976/9 x8x 800/S  
Z977/9,4x8x1200/S

d1	d2
Z976/... = 9 mm 13 mm	Z976/... = 8 mm 12 mm
Z977/... = 9,4 mm	Z977/... = 8 mm

Stück/Piece	Nr./No.	d1	d2	l1 (≥ 100 - ≤ 2600)	S
	/	x	x	/	S
	/	x	x	/	S
	/	x	x	/	S
	/	x	x	/	S
	/	x	x	/	S

Senden Sie Ihre Anfrage bitte an: Please send your quotation to: Merci d'envoyer votre demande à:

Fax: 02351 957-320 oder/or/ou Email: [sonderanfertigungen@hasco.com](mailto:sonderanfertigungen@hasco.com)